


Smooth bored or female threads M3-M8 712

- Operating elements
- Working temperature: -30°C to +140°C
- Materials: black phenolic plastic

Moulded thread

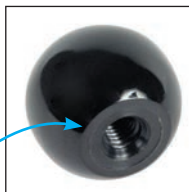


With moulded thread

Brass insert



With threaded insert

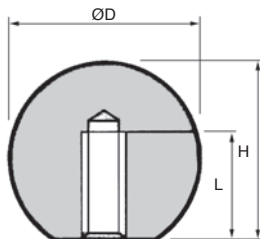

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-20%	-30%	-40%	On request

Part number	Thread ØT	ØD	H	L	Stock*	Price each 1 to 9
With moulded thread						
712-001	M3	10,00	9,50	5,55	✓	1,67 €
712-002	M4	12,00	11,00	7,50	✓	1,67 €
712-003	M4	16,00	15,00	7,50	✓	1,79 €
712-004	M5	20,00	18,00	10,50	✓	1,90 €
712-005	M6	25,00	22,50	13,50	✓	2,26 €
712-006	M8	32,00	29,00	16,00	✓	2,92 €
With threaded insert						
712-007	M4	16,00	15,00	7,50	✓	2,26 €
712-008	M5	20,00	18,00	10,50	✓	2,13 €
712-009	M6	25,00	22,50	13,50	✓	2,83 €
712-010	M8	32,00	29,00	16,00	✓	4,08 €

*Depending on availability - Dimensions in mm