


Buyers guide

Linear motion

Closed bushings



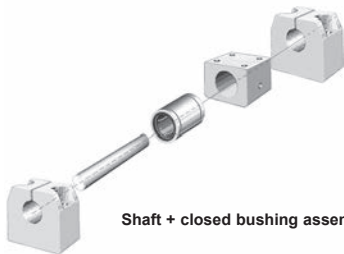


Part number	LBE	KB-WW	KB-UU	KBS	KBS-WW
Description	miniature	massive	massive	massive stainless steel	massive stainless steel
Brand	IKO®	-	NB	NB	-
For shaft size (mm)	Ø3 → Ø5	Ø8 → Ø40	Ø5 → Ø80	Ø8 → Ø60	Ø12 → Ø40
Shaft par number	-	Z-A	Z-A	Z-B	Z-B
Housing unit	-	NSB, S2B	NSB, S2B	NSB, S2B	NSB, S2B
Shaft end	-	SFWR, FGWA	SFWR, FGWA	SFWR, FGWA	SFWR, FGWA
Advantages	small diameters	economy range	high load capacity	high load capacity	economy range
Quality	☆☆☆	☆☆	☆☆☆	☆☆☆	☆☆
Price	€€	€	€€	€€€€	€
Pages	3 238	3 239	3 240	3 241	3 239



Shaft + closed bushing assembly

Open bushings

				
TK	KH	RJUM / RJZM	TK-OP	KB-OP
self aligning Topball®	light	polymer without ball-bearings	self aligning Topball®	massive
NB	-	DryLin®	NB	NB
Ø12 → Ø40	Ø12 → Ø50	Ø5 → Ø50	Ø12 → Ø40	Ø10 → 80
Z-A	Z-A	AWN	FTSN	FTSN
NSB, S2B	SAKH	RJUM05, RJUM06	NSO, S2O	NSO, S2O
SFWR, FGWA	SFWR, FGWA	SFWR, FGWA	-	-
compensates for misalignments	for light loads	not sensitive to dirt	heavy loads, long lengths	heavy loads, long lengths
☆☆☆	☆☆	☆☆☆	☆☆☆	☆☆☆
€€	€	€€	€€€	€€€
3 242	3 236	3 243	3 246	3 245

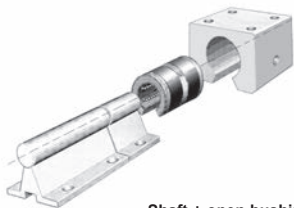

Shaft + open bushing assembly