


- **Trasmette sforzi importanti**
- **Materiale:**
Acciaio C40
- **Fabbricato per estrusione**

Accessori

- Ghiera scanalata cilindrica o con sponde

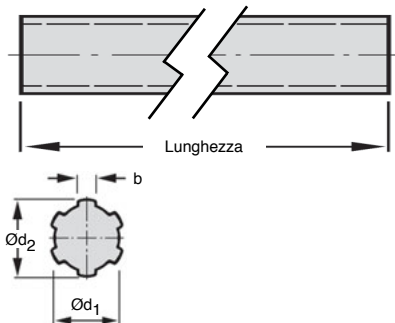

SCONTI PER QUANTITÀ

Qtà	1+	10+	20+	30+	40+
Sc.	Prezzo	-15%	-20%	-30%	Su richiesta

Codice	N. di scanalature	$\varnothing d_1$	$\varnothing d_2$	b	Lunghezza standard (mm)	Massa (kg)	Stock*	Prezzo unit da 1 a 9
ACA6-14-1000	6	11 ^{+0 /-0,08}	14 ^{-0,07/-0,2}	3,0 ^{+0 /-0,08}	1000	0,949	✓	29,11 €
ACA6-16-1000	6	13 ^{+0 /-0,08}	16 ^{-0,07/-0,2}	3,5 ^{+0 /-0,08}	1000	1,287	✓	27,88 €
ACA6-20-1000	6	16 ^{+0 /-0,08}	20 ^{-0,07/-0,25}	4,0 ^{+0 /-0,08}	1000	1,911	✓	37,41 €
ACA6-22-1000	6	18 ^{+0 /-0,08}	22 ^{+0/-0,10}	5,0 ^{-0,07/-0,15}	1000	2,453	✓	42,40 €
ACA6-25-1000	6	21 ^{+0 /-0,08}	25 ^{-0,07/-0,27}	5,0 ^{+0 /-0,08}	1000	3,139	✓	48,48 €
ACA6-28-1000	6	23 ^{+0 /-0,08}	28 ^{-0,07/-0,25}	6,0 ^{+0 /-0,08}	1000	3,964	✓	65,18 €
ACA6-32-1000	6	26 ^{+0 /-0,08}	32 ^{-0,07/-0,27}	6,0 ^{+0 /-0,08}	1000	5,008	✓	79,83 €
ACA6-34-1000	6	28 ^{+0 /-0,08}	34 ^{-0,07/-0,27}	7,0 ^{+0 /-0,08}	1000	5,816	✓	94,20 €
ACA8-38-1000	8	32 ^{+0 /-0,08}	38 ^{-0,07/-0,27}	6,0 ^{+0 /-0,08}	1000	7,433	✓	116,82 €
ACA8-42-1000	8	36 ^{+0 /-0,08}	42 ^{-0,07/-0,27}	7,0 ^{+0 /-0,08}	1000	9,302	✓	151,63 €
ACA8-48-1000	8	42 ^{+0 /-0,08}	48 ^{-0,07/-0,27}	8,0 ^{+0 /-0,08}	1000	12,371	✓	192,36 €
ACA8-54-1000	8	46 ^{+0 /-0,08}	54 ^{-0,07/-0,27}	9,0 ^{+0 /-0,08}	1000	15,300	✓	279,91 €

*Nei limiti delle disponibilità - Dimensioni in mm