

Mounting collar for ball pin

BABFC
BABFO



With a round or oval flange

- For use on thin sheet metal
- These collars offer a quick and securing method of mounting ball pins
- For the construction of boxes or other containers
- Material: 303, stainless steel




Fonctionnement


- The large contact surface area ensures that all the force is spread evenly over thin walled structures

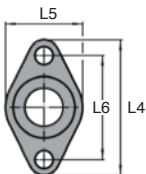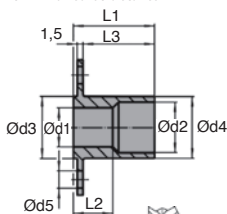

BABFO :
Oval flange

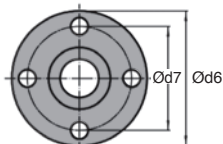

BABFC :
Cylindrical flange

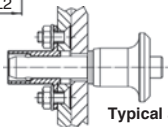

Typical application

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 25+ |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

With cylindrical flange

| Part number | Ød1 | Ød2 | Ød3 | | Ød4 | Ød5 | Ød6 | Ød7 | L1 | L2 | L3 | Weight (g) | Price each 1 to 5 |
|----------------|-----|-----|-------|------|-----|-----|-----|-----|------|------|----|------------|-------------------|
| | | | -0,05 | -0,1 | | | | | | | | | |
| BAB5-8/FC/SS | 5 | 8 | 10 | 9,9 | 3,4 | 25 | 19 | 12 | 5,4 | 9,5 | 9 | 19,01 € | |
| BAB6-8/FC/SS | 6 | 8 | 10 | 9,9 | 3,4 | 25 | 19 | 13 | 5,3 | 10,5 | 9 | 19,01 € | |
| BAB8-10/FC/SS | 8 | 10 | 12 | 11,9 | 4,5 | 30 | 22 | 19 | 10,3 | 16,5 | 14 | 21,15 € | |
| BAB10-13/FC/SS | 10 | 13 | 16 | 15,9 | 4,5 | 35 | 27 | 21 | 10,2 | 18,5 | 24 | 23,38 € | |
| BAB12-15/FC/SS | 12 | 15 | 19 | 18,9 | 4,5 | 40 | 30 | 27 | 15,2 | 24,5 | 41 | 26,60 € | |
| BAB16-20/FC/SS | 16 | 20 | 24 | 23,9 | 5,5 | 50 | 40 | 30 | 15,3 | 27,5 | 63 | 31,25 € | |

With oval flange

| Part number | Ød1 | Ød2 | Ød3 | | Ød4 | Ød5 | L1 | L2 | L3 | L4 | L5 | L6 | Weight (g) | Price each 1 to 5 |
|----------------|-----|-----|-------|------|-----|-----|------|------|----|----|----|----|------------|-------------------|
| | | | -0,05 | -0,1 | | | | | | | | | | |
| BAB5-8/FO/SS | 5 | 8 | 10 | 9,9 | 3,4 | 12 | 5,4 | 9,5 | 25 | 15 | 19 | 6 | 21,95 € | |
| BAB6-8/FO/SS | 6 | 8 | 10 | 9,9 | 3,4 | 13 | 5,3 | 10,5 | 25 | 15 | 19 | 6 | 21,95 € | |
| BAB8-10/FO/SS | 8 | 10 | 12 | 11,9 | 4,5 | 19 | 10,3 | 16,5 | 30 | 18 | 22 | 10 | 24,58 € | |
| BAB10-13/FO/SS | 10 | 13 | 16 | 15,9 | 4,5 | 21 | 10,2 | 18,5 | 35 | 20 | 27 | 19 | 27,19 € | |
| BAB12-15/FO/SS | 12 | 15 | 19 | 18,9 | 4,5 | 27 | 15,2 | 24,5 | 40 | 24 | 30 | 34 | 30,41 € | |
| BAB16-20/FO/SS | 16 | 20 | 24 | 23,9 | 5,5 | 30 | 15,3 | 27,5 | 50 | 30 | 40 | 52 | 33,65 € | |

Dimensions in mm