

### - Self locking

### - Materials

Shaft: Stainless steel 1.4542, precipitation hardened with scratch resistant coating

Spring: Stainless steel

Handle: Black aluminium (RAL9005)

Release button: Black stainless steel

- Working temperature range: -30°C to +150°C

stainless steel





### Advantages

- Push to release
- Easy and quick method of attaching, blocking, adjusting etc... Quickly and easily unlocked for frequently repeated operations.
- Corrosion resistant
- Highly resistant, anti-wear, suitable for heavy duty applications
- Can be used with the CDR retaining cable

### Info.



- Shear resistance conforms to DIN 50141

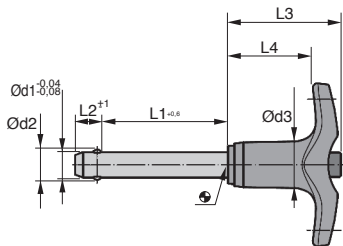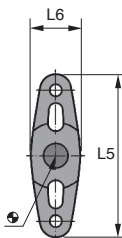

### DISCOUNTS

|       |      |     |      |            |
|-------|------|-----|------|------------|
| Qty.  | 1+   | 6+  | 10+  | 25+        |
| Disc. | List | -5% | -10% | On request |

| Part number | Ød1 | L1 | Ød2 | Ød3  | L2  | L3   | L4   | L5   | L6   | Corresponding bore H11 | Double shear resistance kN min. | Weight (g) | Price each 1 to 5 |
|-------------|-----|----|-----|------|-----|------|------|------|------|------------------------|---------------------------------|------------|-------------------|
| BAB5-10/T   | 5   | 10 | 5,5 | 11,8 | 6,0 | 31,6 | 24,1 | 45,2 | 12,7 | 5                      | 24                              | 19         | 30,54 €           |
| BAB5-15/T   | 5   | 15 | 5,5 | 11,8 | 6,0 | 31,6 | 24,1 | 45,2 | 12,7 | 5                      | 24                              | 20         | 30,54 €           |
| BAB5-20/T   | 5   | 20 | 5,5 | 11,8 | 6,0 | 31,6 | 24,1 | 45,2 | 12,7 | 5                      | 24                              | 20         | 30,54 €           |
| BAB5-25/T   | 5   | 25 | 5,5 | 11,8 | 6,0 | 31,6 | 24,1 | 45,2 | 12,7 | 5                      | 24                              | 21         | 30,54 €           |
| BAB5-30/T   | 5   | 30 | 5,5 | 11,8 | 6,0 | 31,6 | 24,1 | 45,2 | 12,7 | 5                      | 24                              | 22         | 32,44 €           |
| BAB6-10/T   | 6   | 10 | 7,0 | 11,8 | 7,0 | 31,6 | 24,1 | 45,2 | 12,7 | 6                      | 35                              | 20         | 30,54 €           |
| BAB6-15/T   | 6   | 15 | 7,0 | 11,8 | 7,0 | 31,6 | 24,1 | 45,2 | 12,7 | 6                      | 35                              | 21         | 30,54 €           |
| BAB6-20/T   | 6   | 20 | 7,0 | 11,8 | 7,0 | 31,6 | 24,1 | 45,2 | 12,7 | 6                      | 35                              | 22         | 30,54 €           |
| BAB6-25/T   | 6   | 25 | 7,0 | 11,8 | 7,0 | 31,6 | 24,1 | 45,2 | 12,7 | 6                      | 35                              | 23         | 30,54 €           |
| BAB6-30/T   | 6   | 30 | 7,0 | 11,8 | 7,0 | 31,6 | 24,1 | 45,2 | 12,7 | 6                      | 35                              | 24         | 32,44 €           |

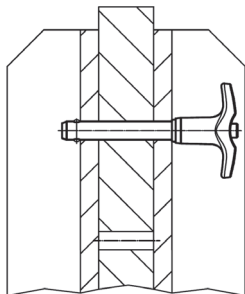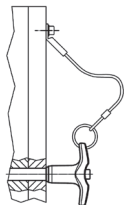

## DISCOUNTS

|       |      |     |      |            |
|-------|------|-----|------|------------|
| Qty.  | 1+   | 6+  | 10+  | 25+        |
| Disc. | List | -5% | -10% | On request |

| Part number | Ød1 | L1 | Ød2  | Ød3  | L2   | L3   | L4   | L5   | L6   | Corresponding bore H11 | Double shear resistance kN min. | Weight (g) | Price each 1 to 5 |
|-------------|-----|----|------|------|------|------|------|------|------|------------------------|---------------------------------|------------|-------------------|
| BAB6-35/T   | 6   | 35 | 7,0  | 11,8 | 7,0  | 31,6 | 24,1 | 45,2 | 12,7 | 6                      | 35                              | 25         | 32,44 €           |
| BAB6-40/T   | 6   | 40 | 7,0  | 11,8 | 7,0  | 31,6 | 24,1 | 45,2 | 12,7 | 6                      | 35                              | 26         | 32,44 €           |
| BAB6-45/T   | 6   | 45 | 7,0  | 11,8 | 7,0  | 31,6 | 24,1 | 45,2 | 12,7 | 6                      | 35                              | 27         | 32,44 €           |
| BAB6-50/T   | 6   | 50 | 7,0  | 11,8 | 7,0  | 31,6 | 24,1 | 45,2 | 12,7 | 6                      | 35                              | 28         | 32,44 €           |
| BAB8-20/T   | 8   | 20 | 9,5  | 14,7 | 8,2  | 35,8 | 26,9 | 51,5 | 15,8 | 8                      | 63                              | 37         | 33,71 €           |
| BAB8-25/T   | 8   | 25 | 9,5  | 14,7 | 8,2  | 35,8 | 26,9 | 51,5 | 15,8 | 8                      | 63                              | 39         | 33,43 €           |
| BAB8-30/T   | 8   | 30 | 9,5  | 14,7 | 8,2  | 35,8 | 26,9 | 51,5 | 15,8 | 8                      | 63                              | 41         | 35,55 €           |
| BAB8-35/T   | 8   | 35 | 9,5  | 14,7 | 8,2  | 35,8 | 26,9 | 51,5 | 15,8 | 8                      | 63                              | 43         | 35,55 €           |
| BAB8-40/T   | 8   | 40 | 9,5  | 14,7 | 8,2  | 35,8 | 26,9 | 51,5 | 15,8 | 8                      | 63                              | 44         | 35,55 €           |
| BAB8-45/T   | 8   | 45 | 9,5  | 14,7 | 8,2  | 35,8 | 26,9 | 51,5 | 15,8 | 8                      | 63                              | 46         | 35,55 €           |
| BAB8-50/T   | 8   | 50 | 9,5  | 14,7 | 8,2  | 35,8 | 26,9 | 51,5 | 15,8 | 8                      | 63                              | 48         | 35,55 €           |
| BAB10-20/T  | 10  | 20 | 12,0 | 14,7 | 9,6  | 35,8 | 26,9 | 51,5 | 15,8 | 10                     | 100                             | 44         | 49,31 €           |
| BAB10-25/T  | 10  | 25 | 12,0 | 14,7 | 9,6  | 35,8 | 26,9 | 51,5 | 15,8 | 10                     | 100                             | 47         | 49,31 €           |
| BAB10-30/T  | 10  | 30 | 12,0 | 14,7 | 9,6  | 35,8 | 26,9 | 51,5 | 15,8 | 10                     | 100                             | 49         | 51,90 €           |
| BAB10-35/T  | 10  | 35 | 12,0 | 14,7 | 9,6  | 35,8 | 26,9 | 51,5 | 15,8 | 10                     | 100                             | 52         | 51,90 €           |
| BAB10-40/T  | 10  | 40 | 12,0 | 14,7 | 9,6  | 35,8 | 26,9 | 51,5 | 15,8 | 10                     | 100                             | 55         | 51,90 €           |
| BAB10-45/T  | 10  | 45 | 12,0 | 14,7 | 9,6  | 35,8 | 26,9 | 51,5 | 15,8 | 10                     | 100                             | 58         | 51,90 €           |
| BAB10-50/T  | 10  | 50 | 12,0 | 14,7 | 9,6  | 35,8 | 26,9 | 51,5 | 15,8 | 10                     | 100                             | 61         | 51,90 €           |
| BAB10-60/T  | 10  | 60 | 12,0 | 14,7 | 9,6  | 35,8 | 26,9 | 51,5 | 15,8 | 10                     | 100                             | 67         | 54,42 €           |
| BAB12-25/T  | 12  | 25 | 14,5 | 18,2 | 10,6 | 35,1 | 25,3 | 59,1 | 20,2 | 12                     | 144                             | 73         | 50,31 €           |
| BAB12-30/T  | 12  | 30 | 14,5 | 18,2 | 10,6 | 35,1 | 25,3 | 59,1 | 20,2 | 12                     | 144                             | 77         | 52,88 €           |
| BAB12-35/T  | 12  | 35 | 14,5 | 18,2 | 10,6 | 35,1 | 25,3 | 59,1 | 20,2 | 12                     | 144                             | 81         | 52,88 €           |
| BAB12-40/T  | 12  | 40 | 14,5 | 18,2 | 10,6 | 35,1 | 25,3 | 59,1 | 20,2 | 12                     | 144                             | 86         | 52,88 €           |
| BAB12-45/T  | 12  | 45 | 14,5 | 18,2 | 10,6 | 35,1 | 25,3 | 59,1 | 20,2 | 12                     | 144                             | 90         | 52,88 €           |
| BAB12-50/T  | 12  | 50 | 14,5 | 18,2 | 10,6 | 35,1 | 25,3 | 59,1 | 20,2 | 12                     | 144                             | 94         | 52,88 €           |
| BAB12-60/T  | 12  | 60 | 14,5 | 18,2 | 10,6 | 35,1 | 25,3 | 59,1 | 20,2 | 12                     | 144                             | 103        | 55,33 €           |
| BAB12-70/T  | 12  | 70 | 14,5 | 18,2 | 10,6 | 35,1 | 25,3 | 59,1 | 20,2 | 12                     | 144                             | 111        | 55,33 €           |
| BAB12-80/T  | 12  | 80 | 14,5 | 18,2 | 10,6 | 35,1 | 25,3 | 59,1 | 20,2 | 12                     | 144                             | 119        | 57,76 €           |