

# Split shaft collar with clamp lever

## BAG-MI

## Steel

- Ensures a uniform distribution of the clamping force
- Clamps securely to any type of shaft
- Material:

Burnished steel (S250Pb)

Repeated operations

 



### Advantages

- Fits perfectly on to the shaft with a high clamping force but without risk of damage

### Info.

- Recommended shaft tolerance: h11

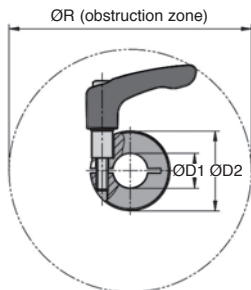

### DISCOUNTS

| Qty   | 1+   | 6+   | 20+  | 40+        |
|-------|------|------|------|------------|
| Disc. | List | -15% | -20% | On request |

| Part number | ØD1 | ØD2 | B  | ØR    | Stock* | Price each 1 to 5 |
|-------------|-----|-----|----|-------|--------|-------------------|
| BAG1-010-MI | 10  | 24  | 9  | 44,1  | -      | 14,83 €           |
| BAG1-012-MI | 12  | 28  | 11 | 90,4  | ✓      | 15,16 €           |
| BAG1-015-MI | 15  | 34  | 13 | 105,0 | -      | 16,38 €           |
| BAG1-016-MI | 16  | 34  | 13 | 105,0 | ✓      | 16,73 €           |
| BAG1-018-MI | 18  | 36  | 13 | 105,7 | -      | 17,46 €           |
| BAG1-020-MI | 20  | 40  | 15 | 103,8 | ✓      | 18,26 €           |
| BAG1-022-MI | 22  | 42  | 15 | 104,2 | -      | 18,26 €           |
| BAG1-025-MI | 25  | 45  | 15 | 104,8 | ✓      | 19,34 €           |
| BAG1-028-MI | 28  | 48  | 15 | 106,8 | -      | 19,34 €           |
| BAG1-030-MI | 30  | 54  | 15 | 112,6 | ✓      | 22,20 €           |
| BAG1-040-MI | 40  | 60  | 15 | 113,2 | -      | 25,18 €           |
| BAG1-050-MI | 50  | 78  | 19 | 150,2 | -      | 46,79 €           |

Dimensions in mm