







# Clamping collar



## BAP

## Ø10 à Ø18

- 2 part clamping collar
- Bore smooth or grooved
- Materials:  
Body: reinforced polyamide  
Screws: stainless steel 304

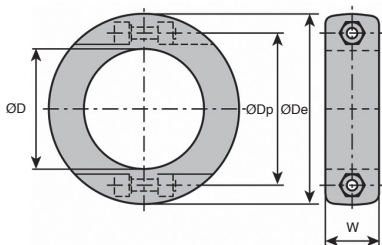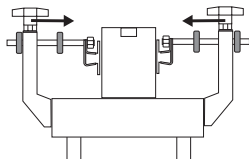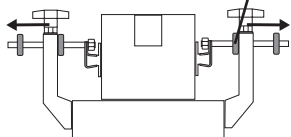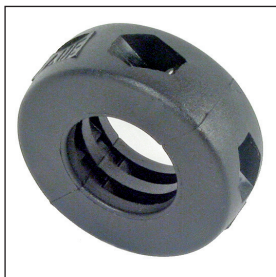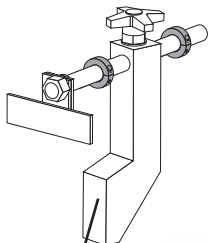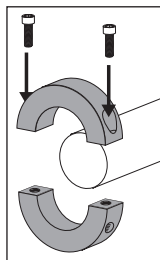

### DISCOUNTS

Qté	1+	40+	100+	200+	300+
Rem. Prix		-5%	-10%	-15%	On request

Part number	ØD	ØDe	ØDp	W	Weight (kg)	Stock*	Price each. 1 à 39
BAP-10	10	30	20	12	0,01	✓	2,93 €
BAP-12	12	30	20	12	0,01	✓	2,93 €
BAP-14	14	30	20	12	0,01	✓	2,93 €
BAP-15	15	39	27	14	0,02	✓	2,93 €
BAP-16	16	39	27	14	0,02	✓	2,93 €
BAP-18	18	39	27	14	0,02	-	2,93 €

\*Depending on availability - Dimensions in mm