

# Imperial joint kit, NBR90Sh A

## BOX-TOR-INCH For fasteners and fittings


- Selection of BS imperial sizes
- 7 sizes
- Material:  
Nitrile NBR 90 shore A/ST
- Working temperature range: -30° to +110°C

### Applications

- Suitable for:
- Hydraulic fluids
  - HFA fluids
  - HFB fluids
  - HFC fluids
  - Air

### Info

- Ideal for use in the maintenance dept

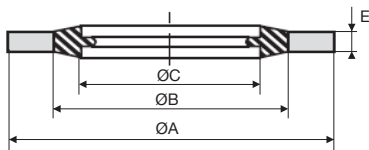

### Box contents

| Quantity | For thread | A <sup>+0,13</sup> <sub>0</sub> | B <sup>+0,13</sup> | C <sup>+0,13</sup> | E <sup>+0,15</sup> |
|----------|------------|---------------------------------|--------------------|--------------------|--------------------|
| 25       | 1/8"BSP    | 15,88                           | 11,84              | 10,37              | 2,0                |
| 25       | 1/4"BSP    | 20,57                           | 15,21              | 13,74              | 2,0                |
| 15       | 3/8"BSP    | 23,80                           | 18,75              | 17,28              | 2,0                |
| 15       | 1/2"BSP    | 28,58                           | 23,01              | 21,54              | 2,5                |
| 15       | 5/8"BSP    | 31,75                           | 24,9               | 23,49              | 2,5                |
| 15       | 3/4"BSP    | 34,93                           | 28,53              | 27,05              | 2,5                |
| 4        | 1"BSP      | 42,80                           | 36,88              | 33,89              | 3,2                |

### DISCOUNTS

| Qty   | 1+  | 3+  | 5+         |
|-------|-----|-----|------------|
| Disc. | Net | -5% | On request |

| Part N°      | Material    | Qty per box | Price each<br>1 to 2 |
|--------------|-------------|-------------|----------------------|
| BOX-TOR-INCH | NBR 90 Sh A | 114 pieces  | 55,52 €              |

All dimensions in mm