

# Ball transfer unit in blue certified plastic

Suitable for foodstuff sector

BPPEBLU




- The ball transfer units are made of a certified blue plastic which is suitable for use in the foodstuff sector
- Press-in assembly
- Conveying speed up to 1.5 m/s
- Foodstuff conform: Food Grade, EU Regulation 1935/2004, EU Regulation 10/2011
- Material :
  - Housing and cap POM
  - Bearing ball stainless steel
  - Load ball stainless steel or plastic
- Temperature range: -30 °C to +50 °C (up to +30°C with plastic load balls)

## Advantages

- The ball transfer units are equipped with a gap-free and sealed cap, which prevents the formation of soiled edge
- The dirt holes underneath the housing enable particularly easy cleaning of the ball transfer units



**Food industry**  
**NEW!**

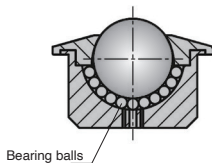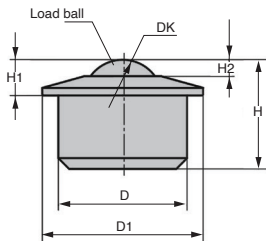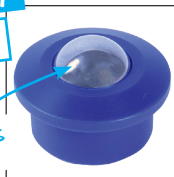

## DISCOUNTS

Qty	1+	6+	20+	30+
Disc.	List	-10%	-15%	On request

Part number	ØD	ØD1	ØDK	H	H1	H2	Load rating C (kg)	Price each 1 to 5
<b>Load ball in POM</b>								
BPPE15-24/PP/BLU	24±0,1	31±0,2	15,875	20,5±0,2	9,5±0,2	4,5	20	
BPPE22-36/PP/BLU	36±0,1	45±0,2	22,225	30,5±0,2	10±0,2	4,5	25	
BPPE30-45/PP/BLU	45±0,1	55±0,1	30,000	37±0,1	14±0,1	5,5	35	
BPPE45-62/PP/BLU	62±0,1	75±0,1	44,500	53,5±0,1	19±0,1	9,0	50	
<b>Load ball in stainless steel</b>								
BPPE15-24/SS/BLU	24±0,1	31±0,2	15,875	20,5±0,2	9,5±0,2	4,5	20	
BPPE22-36/SS/BLU	36±0,1	45±0,2	22,225	30,5±0,2	10±0,2	4,5	25	
BPPE30-45/SS/BLU	45±0,1	55±0,1	30,000	37±0,1	14±0,1	5,5	35	
BPPE45-62/SS/BLU	62±0,1	75±0,1	44,500	53,5±0,1	19±0,1	9,0	50	

All dimensions in mm.