

Flanged drill bushing

CDPC

Treated steel

- For guiding drill bits during repetitive drilling or countersinking operations
- Good resistance in operation
- Material:
Case hardened steel

Info.

- Bore tolerance: DH7

Advantages

- Facilitates the drilling operation and avoids wear of the drill bit
- Ensures high repeatability




DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	List	-5%	-10%	On request

Part number	Ød1	I1	Ød2 (n6)	Ød3	I2	Weight (g)	Price each 1 to 4	Part number	Ød1	I1	Ød2 (n6)	Ød3	I2	Weight (g)	Price each 1 to 4
CDPC2-5-6	2	6	5	8	2	1,2	5,32 €	CDPC5-1-10-20	5,1	20	10	13	3	10	9,30 €
CDPC2-5-9	2	9	5	8	2	1,6	5,73 €	CDPC5-5-10-10	5,5	10	10	13	3	5,3	4,95 €
CDPC2-1-5-6	2,1	6	5	8	2	1,2	5,32 €	CDPC5-5-10-16	5,5	16	10	13	3	7,9	5,58 €
CDPC2-1-5-9	2,1	9	5	8	2	1,5	5,73 €	CDPC5-5-10-20	5,5	20	10	13	3	9,6	9,30 €
CDPC2-5-5-6	2,5	6	5	8	2	1,1	5,32 €	CDPC6-10-10	6	10	10	13	3	4,9	4,95 €
CDPC2-5-5-9	2,5	9	5	8	2	1,4	5,73 €	CDPC6-10-16	6	16	10	13	3	7,3	5,58 €
CDPC3-6-8	3	8	6	9	2,5	1,9	5,24 €	CDPC6-10-20	6	20	10	13	3	8,8	9,30 €
CDPC3-6-12	3	12	6	9	2,5	2,6	5,73 €	CDPC6-1-12-10	6,1	10	12	15	3	7,7	5,58 €
CDPC3-6-16	3	16	6	9	2,5	3,2	10,01 €	CDPC6-1-12-16	6,1	16	12	15	3	12	6,09 €
CDPC3-1-6-8	3,1	8	6	9	2,5	1,9	5,24 €	CDPC6-1-12-20	6,1	20	12	15	3	14	9,90 €
CDPC3-1-6-12	3,1	12	6	9	2,5	2,5	5,73 €	CDPC6-5-12-10	6,5	10	12	15	3	7,4	5,58 €
CDPC3-1-6-16	3,1	16	6	9	2,5	3,2	10,01 €	CDPC6-5-12-16	6,5	16	12	15	3	11	6,09 €
CDPC3-5-7-8	3,5	8	7	10	2,5	2,4	4,95 €	CDPC6-5-12-20	6,5	20	12	15	3	14	9,90 €
CDPC3-5-7-12	3,5	12	7	10	2,5	3,4	5,58 €	CDPC7-12-10	7	10	12	15	3	7	5,58 €
CDPC3-5-7-16	3,5	16	7	10	2,5	4,3	10,01 €	CDPC7-12-16	7	16	12	15	3	10	6,09 €
CDPC4-7-8	4	8	7	10	2,5	2,3	4,95 €	CDPC7-12-20	7	20	12	15	3	13	9,90 €
CDPC4-7-12	4	12	7	10	2,5	3,1	5,58 €	CDPC7-1-12-10	7,1	10	12	15	3	6,9	5,58 €
CDPC4-7-16	4	16	7	10	2,5	3,9	10,01 €	CDPC7-1-12-16	7,1	16	12	15	3	10	6,09 €
CDPC4-1-8-8	4,1	8	8	11	2,5	3	4,80 €	CDPC7-1-12-20	7,1	20	12	15	3	13	9,90 €
CDPC4-1-8-12	4,1	12	8	11	2,5	4,2	5,09 €	CDPC7-5-12-10	7,5	10	12	15	3	6,5	5,58 €
CDPC4-1-8-16	4,1	16	8	11	2,5	5,3	8,59 €	CDPC7-5-12-16	7,5	16	12	15	3	9,7	6,09 €
CDPC4-5-8-8	4,5	8	8	11	2,5	2,9	4,80 €	CDPC7-5-12-20	7,5	20	12	15	3	12	9,90 €
CDPC4-5-8-12	4,5	12	8	11	2,5	3,9	5,09 €	CDPC8-12-10	8	10	12	15	3	6	5,58 €
CDPC4-5-8-16	4,5	16	8	11	2,5	5	8,59 €	CDPC8-12-16	8	16	12	15	3	9	6,09 €
CDPC5-8-8	5	8	8	11	2,5	2,6	4,80 €	CDPC8-12-20	8	20	12	15	3	11	9,90 €
CDPC5-8-12	5	12	8	11	2,5	3,6	5,09 €	CDPC8-1-15-12	8,1	12	15	18	3	13	6,32 €
CDPC5-8-16	5	16	8	11	2,5	4,5	8,59 €	CDPC8-1-15-20	8,1	20	15	18	3	25	6,85 €
CDPC5-1-10-10	5,1	10	10	13	3	5,5	4,95 €	CDPC8-1-15-25	8,1	25	15	18	3	26	10,73 €
CDPC5-1-10-16	5,1	16	10	13	3	8,2	5,58 €	CDPC8-5-15-12	8,5	12	15	18	3	13	6,32 €

Dimensions in mm

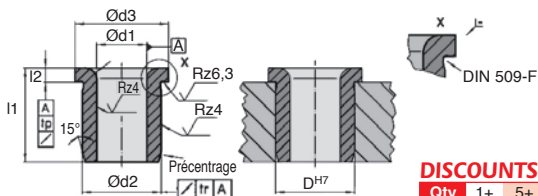

DISCOUNTS

Qty Disc.	1+	5+	10+	20+
	List	-5%	-10%	On request

Part number	Ød1	l1	Ød2 (n6)	Ød3	l2	Weight (g)	Price each 1 to 4	Part number	Ød1	l1	Ød2 (n6)	Ød3	l2	Weight (g)	Price each 1 to 4
CDPC8.5-15-20	8,5	20	15	18	3	20	6,85 €	CDPC13-22-36	13	36	22	26	4	73	16,15 €
CDPC8.5-15-25	8,5	25	15	18	3	25	10,73 €	CDPC14-22-16	14	16	22	26	4	32	7,84 €
CDPC9-15-12	9	12	15	18	3	12	6,32 €	CDPC14-22-28	14	28	22	26	4	53	11,05 €
CDPC9-15-20	9	20	15	18	3	19	6,85 €	CDPC14-22-36	14	36	22	26	4	67	16,15 €
CDPC9-15-25	9	25	15	18	3	23	10,73 €	CDPC15-22-16	15	16	22	26	4	29	7,84 €
CDPC9.1-15-12	9,1	12	15	18	3	12	6,32 €	CDPC15-22-28	15	28	22	26	4	48	11,05 €
CDPC9.1-15-20	9,1	20	15	18	3	19	6,85 €	CDPC15-22-36	15	36	22	26	4	61	16,15 €
CDPC9.1-15-25	9,1	25	15	18	3	23	10,73 €	CDPC16-26-16	16	16	26	30	4	45	9,90 €
CDPC9.5-15-12	9,5	12	15	18	3	11	6,32 €	CDPC16-26-28	16	28	26	30	4	76	12,95 €
CDPC9.5-15-20	9,5	20	15	18	3	18	6,85 €	CDPC16-26-36	16	36	26	30	4	97	17,72 €
CDPC9.5-15-25	9,5	25	15	18	3	22	10,73 €	CDPC16.1-26-16	16,1	16	26	30	4	45	14,13 €
CDPC10-15-12	10	12	15	18	3	11	6,32 €	CDPC16.1-26-28	16,1	28	26	30	4	76	17,51 €
CDPC10-15-20	10	20	15	18	3	17	6,85 €	CDPC16.1-26-36	16,1	36	26	30	4	96	22,93 €
CDPC10-15-25	10	25	15	18	3	20	10,73 €	CDPC16.5-26-16	16,5	16	26	30	4	44	9,90 €
CDPC10.1-18-12	10,1	12	18	22	4	20	6,85 €	CDPC16.5-26-28	16,5	28	26	30	4	73	12,95 €
CDPC10.1-18-20	10,1	20	18	22	4	30	7,46 €	CDPC16.5-26-36	16,5	36	26	30	4	93	17,57 €
CDPC10.1-18-25	10,1	25	18	22	4	37	11,46 €	CDPC17-26-16	17	16	26	30	4	42	9,90 €
CDPC10.5-18-12	10,5	12	18	22	4	19	6,85 €	CDPC17-26-28	17	28	26	30	4	70	12,95 €
CDPC10.5-18-20	10,5	20	18	22	4	29	7,46 €	CDPC17-26-36	17	36	26	30	4	90	17,57 €
CDPC10.5-18-25	10,5	25	18	22	4	36	11,46 €	CDPC18-26-16	18	16	26	30	4	39	9,90 €
CDPC11-18-12	11	12	18	22	4	18	6,85 €	CDPC18-26-28	18	28	26	30	4	64	12,95 €
CDPC11-18-20	11	20	18	22	4	28	7,46 €	CDPC18-26-36	18	36	26	30	4	82	17,57 €
CDPC11-18-25	11	25	18	22	4	34	11,46 €	CDPC19-30-20	19	20	30	34	5	71	12,95 €
CDPC11.1-18-12	11,1	12	18	22	4	18	6,85 €	CDPC19-30-36	19	36	30	34	5	125	17,20 €
CDPC11.1-18-20	11,1	20	18	22	4	28	7,46 €	CDPC19-30-45	19	45	30	34	5	154	25,79 €
CDPC11.1-18-25	11,1	25	18	22	4	34	11,46 €	CDPC20-30-20	20	20	30	34	5	67	12,95 €
CDPC10.1-18-12	11,5	12	18	22	4	17	6,85 €	CDPC20-30-36	20	36	30	34	5	0	17,20 €
CDPC11.5-18-20	11,5	20	18	22	4	26	7,46 €	CDPC20-30-45	20	45	30	34	5	143	25,79 €
CDPC11.5-18-25	11,5	25	18	22	4	33	11,46 €	CDPC20.1-30-20	20,1	20	30	34	5	66	17,20 €
CDPC12-18-12	12	12	18	22	4	16	6,85 €	CDPC20.1-30-36	20,1	36	30	34	5	115	22,52 €
CDPC12-18-20	12	20	18	22	4	25	7,46 €	CDPC20.1-30-45	20,1	45	30	34	5	142	32,96 €
CDPC12-18-25	12	25	18	22	4	31	11,46 €	CDPC22-30-20	22	20	30	34	5	56	12,95 €
CDPC12.1-22-16	12,1	16	22	26	4	37	7,84 €	CDPC22-30-36	22	36	30	34	5	97	17,20 €
CDPC12.1-22-28	12,1	28	22	26	4	62	11,05 €	CDPC22-30-45	22	45	30	34	5	120	25,79 €
CDPC12.1-22-36	12,1	36	22	26	4	78	16,15 €	CDPC25-35-20	25	20	35	39	5	80	16,62 €
CDPC12.5-22-16	12,5	16	22	26	4	36	7,84 €	CDPC25-35-36	25	36	35	39	5	138	20,44 €
CDPC12.5-22-28	12,5	28	22	26	4	60	11,05 €	CDPC25-35-45	25	45	35	39	5	171	30,46 €
CDPC12.5-22-36	12,5	36	22	26	4	76	16,15 €	CDPC30-42-25	30	25	42	46	5	139	24,81 €
CDPC13-22-16	13	16	22	26	4	34	7,84 €	CDPC30-42-45	30	45	42	46	5	245	29,39 €
CDPC13-22-28	13	28	22	26	4	58	11,05 €	CDPC30-42-56	30	56	42	46	5	304	44,81 €

Dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel