


New

Worm and wheel gearbox

Integrated torque limiter up to 57 Nm CHML40

- **Protected against overload**
- Ratios from 20:1 to 100:1
- Torque limit can be set anywhere up to the maximum value
- Materials:
 - Casing: aluminium
 - Worm: treated steel
 - Wheel: bronze (cast iron hub)
- Lubrication: synthetic oil ISO VG320

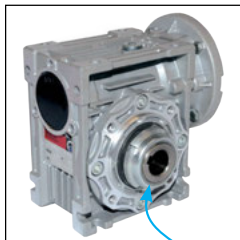


Accessory

- See **CHM40**

Info

- Dimensions are the same as the **CHM** range except for the mounting flanges which may be different

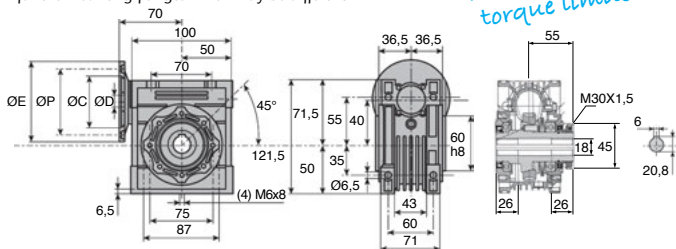

OUTPUT TORQUE (IN Nm, VALUES GIVEN AS A GUIDE ONLY)

Ratio	20:1	25:1	30:1	40:1	50:1	60:1	100:1
Input speed (rpm)	2800	28	27	33	30	30	27
1400	38	39	44	40	38	35	28
900	43	43	48	44	41	38	31
500	53	51	57	52	48	40	35

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	Reduction		Mounting				Self locking		Price each
	ratio	flange	ØD	ØC	ØP	ØE	output	1 to 5	
CHML40-20-71B14	20:1	71B14	14	70	85	105	No	203,70 €	
CHML40-25-63B14	25:1	63B14	11	60	75	90	No	203,70 €	
CHML40-25-63B5	25:1	63B5	11	95	115	140	No	203,70 €	
CHML40-30-63B14	30:1	63B14	11	60	75	90	No	203,70 €	
CHML40-30-63B5	30:1	63B5	11	95	115	140	No	203,70 €	
CHML40-40-63B14	40:1	63B14	11	60	75	90	No	203,70 €	
CHML40-40-63B5	40:1	63B5	11	95	115	140	No	203,70 €	
CHML40-50-63B14	50:1	63B14	11	60	75	90	Not defined	203,70 €	
CHML40-60-63B14	60:1	63B14	11	60	75	90	Not defined	203,70 €	
CHML40-100-63B14	100:1	63B14	11	60	75	90	Yes	203,70 €	

Dimensions in mm