


CLL CLLP

Acciaio


- Forcella d'assemblaggio
- Acciaio semiduro 95 Mn Pb28
R = 500N/mm²
- A norma DIN 71752
- Venduto a multipli, contattateci

Assemblaggio rapido

CLL Forcella

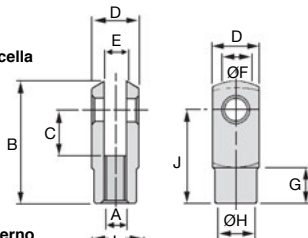

CLLP Perno

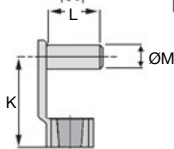

SCONTI PER QUANTITÀ

Qtà	1+	6+	20+	50+	100+	250+
Sc.	Prezzo	-10%	-20%	-30%	-40%	Su richiesta

Forcella

Codice	A	B	C	D	E (B13)	ØF (H9)	G	ØH	J	Carico statico Co (daN)	Stock*	Prezzo unit. da 1 a 5
CLL-5	M5 x 0,80	36	20	10	5	5	7,50	9	30	500	✓	1,69 €
CLL-6	M6 x 1,00	43	24	12	6	6	9,00	10	36	720	✓	1,80 €
CLL-8	M8 x 1,25	58	32	16	8	8	12,00	14	48	1280	✓	2,61 €
CLL-10	M10 x 1,5	72	40	20	10	10	15,00	18	60	2000	✓	4,38 €
CLL-12	M12 x 1,75	86	48	24	12	12	18,00	20	72	2880	✓	7,08 €

Perno a molla

Codice	K	L	ØM	Stock*	Prezzo unit. da 1 a 5
CLLP-5	29	12	5	✓	0,72 €
CLLP-6	35	14	6	✓	0,72 €
CLLP-8	47	19	8	✓	0,78 €
CLLP-10	59	23	10	✓	0,88 €
CLLP-12	71	28	12	✓	1,49 €

*Nei limiti delle disponibilità - Dimensioni in mm