

# Idler for plate chain



## DBL820 For chain ranges 820 and 815

- For use with CAP820 and CAP815 plate chains

- Materials:

Low friction acetal  
Stainless steel screws



- Operating temp.: -40°C to +85°C

(+70°C in humid environments)

- For dimensions and bore tolerances,  
please refer to technical pages

### Advantage

- Two part design facilitates easy assembly

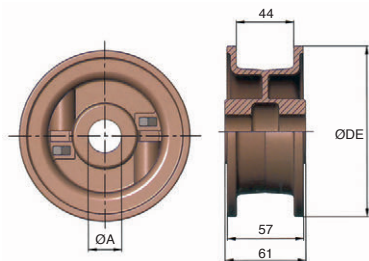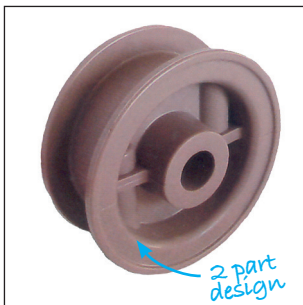

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL820-21-25	129	25	0,3	11,71 €
DBL820-21-30	129	30	0,3	11,71 €
DBL820-21-35	129	35	0,3	11,71 €
DBL820-21-40	129	40	0,3	11,71 €
DBL820-23-25	141	25	0,4	13,14 €
DBL820-23-30	141	30	0,4	13,14 €
DBL820-23-35	141	35	0,4	13,14 €
DBL820-23-40	141	40	0,4	13,53 €
DBL820-25-25	153	45	0,4	13,39 €
DBL820-25-30	153	30	0,4	13,39 €
DBL820-25-35	153	35	0,4	13,39 €
DBL820-25-40	153	40	0,4	13,39 €

Dimensions in mm