


- For use with CAP880T plate chains
- Materials:
 - Low friction acetal
- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

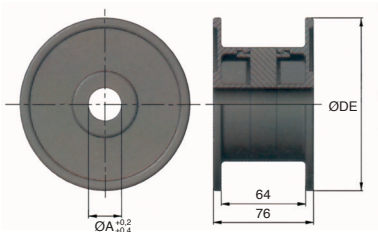

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL880-19-25	118,0	25	0,3	11,71 €
DBL880-19-30	118,0	30	0,3	11,71 €
DBL880-19-35	118,0	35	0,3	11,71 €
DBL880-19-40	118,0	40	0,3	11,71 €
DBL880-21-25	129,8	25	0,3	12,21 €
DBL880-21-30	129,8	30	0,3	12,21 €
DBL880-21-35	129,8	35	0,3	12,21 €
DBL880-21-40	129,8	40	0,3	12,21 €
DBL880-23-25	142,2	25	0,3	13,53 €
DBL880-23-30	142,2	30	0,3	13,53 €
DBL880-23-35	142,2	35	0,3	13,53 €
DBL880-23-40	142,2	40	0,3	13,43 €
DBL880-25-25	154,7	25	0,4	14,24 €
DBL880-25-30	154,7	30	0,4	14,24 €
DBL880-25-35	154,7	35	0,4	14,24 €
DBL880-25-40	154,7	40	0,4	14,24 €

Dimensions in mm