
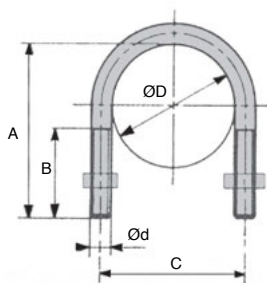
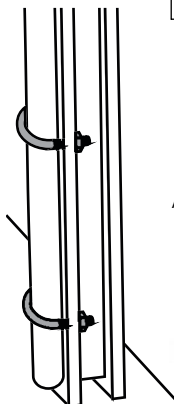


- Consegnato con 2 dadi
- Materiali:  
Inox 304

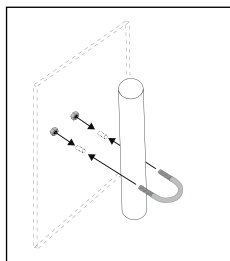

**SCONTI PER QUANTITÀ**

Qtà	1+	101+	201+	301+	401+
Sc. Prezzo	-5%	-10%	-15%	Su richiesta	

Codice	Per tubo Ø esterno ØD	Interno quota in pollici d	Filetto Ød	A (mm)	B (mm)	C (mm)	Stock*	Prezzo Unit. da 1 a 100
EIM013	13	1/4	M6	28	20	19	-	1,19 €
EIM017	17	3/8	M6	36	22	23	-	1,45 €
EIM021	21	1/2	M6	40	20	27	✓	1,52 €
EIM027	27	3/4	M8	50	30	35	✓	2,79 €
EIM034	34	1	M8	55	30	42	✓	3,06 €
EIM042	42	1 <sup>1/4</sup>	M8	68	35	50	✓	3,46 €
EIM049	49	1 <sup>1/2</sup>	M8	70	35	57	✓	3,58 €
EIM060	60	2	M8	80	35	68	✓	3,71 €
EIM076	76	2 <sup>1/2</sup>	M8	110	45	84	-	4,46 €
EIM089	89	3	M10	115	45	99	-	8,02 €
EIM114	114	4	M10	156	55	124	-	9,06 €

\*Nei limiti delle disponibilità - Dimensioni in mm