

Quick fitting cable terminals

Sta

ERCss
ERLss

Fork and eye versions

- Cable terminals for wires, manual crimping

- Material: Stainless steel 316

Advantages

- Rapid manual assembly




ERL Eye




ERC Fork

stainless steel


Manually crimped

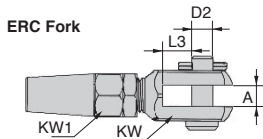


ERC Fork

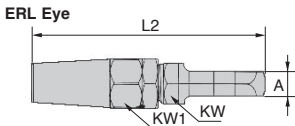

ERL Eye

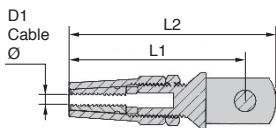

D1
Cable
Ø

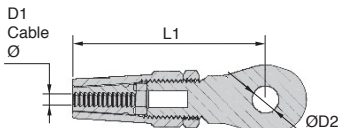

D1
Cable
Ø

DISCOUNTS

Qty.	1+	6+	20+	50+
Disc.	Price -10%	-20%	On request	

Part number	ØD1	ØD2	A	L1	L2	L3	KW	KW1	Weight (g)	Price each 1 to 5
Fork										
ERC3-6/SS	3	6	6,25	49,0	57,0	8,0	12	14	40	24,84 €
ERC4-8/SS	4	8	7,90	60,5	71,4	8,3	14	19	80	29,21 €
ERC5-10/SS	5	10	9,70	69,0	79,0	10,0	16	22	120	34,52 €
ERC6-12/SS	6	12	11,00	81,0	93,0	12,0	19	27	210	43,41 €
ERC8-14/SS	8	14	13,00	106,0	120,0	15,0	24	30	376	59,71 €
Eye										
ERL3-6/SS	3	6	6	48	57	-	10	12	34	26,04 €
ERL4-8/SS	4	8	7	56	69	-	14	14	62	29,72 €
ERL5-10/SS	5	10	8	66	82	-	14	16	88	35,06 €
ERL6-13/SS	6	13	9	83	100	-	17	19	154	42,80 €
ERL8-14/SS	8	14	10	102	123	-	19	24	278	56,40 €