



- Dado per vite a sfere
- Gioco assiale: 0,05mm per un passo di 5mm  
0,1mm per un passo di 10mm
- Materiale:  
16 MnCr5 o 100Cr6

### Accessori


- Vedere vite KGS

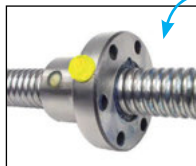

Vite KGS

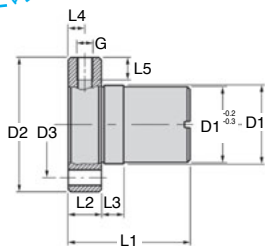

Dado GBS

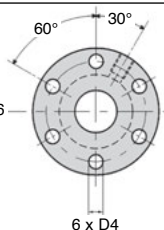

### SCONTI PER QUANTITÀ

|            |     |      |              |     |
|------------|-----|------|--------------|-----|
| Qtà        | 1+  | 2+   | 6+           | 11+ |
| Sc. Prezzo | -7% | -13% | Su richiesta |     |

| Codice        | D1 g6 | D2 h13 | D3 | D4  | L1 | L2 | L3 | L4 | L5 | G      |
|---------------|-------|--------|----|-----|----|----|----|----|----|--------|
| GBS-F-1605-RH | 28    | 48     | 38 | 5,5 | 44 | 12 | 8  | 6  | 8  | M6     |
| GBS-F-2005-RH | 32    | 55     | 45 | 7,0 | 44 | 12 | 8  | 6  | 8  | M6     |
| GBS-F-2505-RH | 38    | 62     | 50 | 7,0 | 46 | 14 | 8  | 7  | 8  | M6     |
| GBS-F-3205-RH | 45    | 70     | 58 | 7,0 | 59 | 16 | 10 | 8  | 8  | M6     |
| GBS-F-3210-RH | 53    | 80     | 68 | 7,0 | 73 | 16 | 10 | 8  | 8  | M8 x 1 |
| GBS-F-4005-RH | 53    | 80     | 68 | 7,0 | 59 | 16 | 10 | 8  | 8  | M6     |
| GBS-F-4010-RH | 63    | 95     | 78 | 9,0 | 73 | 16 | 10 | 8  | 8  | M8 x 1 |

| Codice        | Avanzamento |               |                 | Carico statico Co (kN) | Massa (kg) | Stock* | Prezzo unit. |
|---------------|-------------|---------------|-----------------|------------------------|------------|--------|--------------|
|               | Per vite Ø  | per giro (mm) | dinamico C (kN) |                        |            |        |              |
| GBS-F-1605-RH | 16          | 5             | 7,0             | 12,7                   | 0,20       | ✓      | 205,78 €     |
| GBS-F-2005-RH | 20          | 5             | 7,0             | 17,0                   | 0,25       | ✓      | 209,85 €     |
| GBS-F-2505-RH | 25          | 5             | 9,5             | 22,4                   | 0,35       | ✓      | 255,95 €     |
| GBS-F-3205-RH | 32          | 5             | 17,0            | 49,0                   | 0,55       | ✓      | 337,32 €     |
| GBS-F-3210-RH | 32          | 10            | 25,7            | 56,0                   | 0,90       | ✓      | 351,54 €     |
| GBS-F-4005-RH | 40          | 5             | 19,0            | 63,5                   | 0,80       | ✓      | 340,77 €     |
| GBS-F-4010-RH | 40          | 10            | 30,0            | 70,0                   | 1,20       | -      | 403,00 €     |

\*Nei limiti delle disponibilità - Dimensioni in mm