

- DIN 648, serie E, ISO 6124/1


- Materiale:

Acciaio

### Vantaggio

- Non richiede manutenzione

**Senza manutenzione**

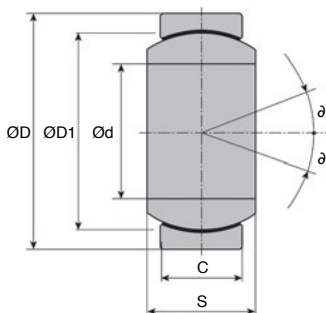

### SCONTI PER QUANTITÀ

Qtà	1+	6+	20+	40+	60+	100+
Sc.	-10%	-15%	-20%	-30%	Su richiesta	

Codice	Ød	ØD	ØD1	S	C	δ	Capacità di carico		Massa (g)	Prezzo unit. da 1 a 5
							statico (N)	dinamico (N)		
GE6C	6 <sup>+0,008</sup>	14 <sup>+0,008</sup>	10,0	6 <sup>+0,12</sup>	4 <sup>+0,24</sup>	13°	9000	3600	4	4,93 €
GE8C	8 <sup>+0,008</sup>	16 <sup>+0,008</sup>	13,0	8 <sup>+0,12</sup>	5 <sup>+0,24</sup>	15°	14600	5850	7	5,42 €
GE10C	10 <sup>+0,008</sup>	19 <sup>+0,009</sup>	16,0	9 <sup>+0,12</sup>	6 <sup>+0,24</sup>	12°	21600	8650	10	5,42 €
GE12C	12 <sup>+0,008</sup>	22 <sup>+0,009</sup>	18,0	10 <sup>+0,12</sup>	7 <sup>+0,24</sup>	11°	28500	11400	10	5,91 €
GE15C	15 <sup>+0,008</sup>	26 <sup>+0,009</sup>	22,0	12 <sup>+0,12</sup>	9 <sup>+0,24</sup>	8°	44000	17600	20	7,15 €
GE17C	17 <sup>+0,008</sup>	30 <sup>+0,009</sup>	25,0	14 <sup>+0,12</sup>	10 <sup>+0,24</sup>	10°	56000	22400	30	8,14 €
GE20C	20 <sup>+0,010</sup>	35 <sup>+0,011</sup>	29,0	16 <sup>+0,12</sup>	12 <sup>+0,24</sup>	9°	78000	31500	60	8,65 €
GE25C	25 <sup>+0,010</sup>	42 <sup>+0,011</sup>	35,5	20 <sup>+0,12</sup>	16 <sup>+0,24</sup>	7°	127000	51000	110	9,65 €
GE30C	30 <sup>+0,010</sup>	47 <sup>+0,011</sup>	40,7	22 <sup>+0,12</sup>	18 <sup>+0,24</sup>	6°	166000	65500	140	11,37 €

\*Nei limiti delle disponibilità - Dimensioni in mm