


Cylindrical polymer bush



JSM

The speed specialist

- Material: iglidur® J, see JFM bush
- Not sold individually, please contact us for details

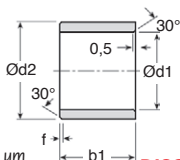

Assembly

- Recommended assembly tolerances shaft h9, housing bore-size H7
- Shaft tr. 50 HRC, surface roughness 0.8-2 µm

Options

- Bore diameter up to 50mm

DISCOUNTS

Qty	1+	10+	25+	50+	100+200+	500+
Disc.	List	-10%	-25%	-40%	-50%	-60%
						On request

Part number	Ød1	Ød2	b1 (h13)	f	Stock*	Price each 1 to 9
JSM0104-02	1,5 +0,014 +0,054	4,0	2,0	0,5	✓	2,36 €
JSM0205-02	2,0 +0,014 +0,054	5,0	2,0	0,5	✓	2,47 €
JSM0206-02	2,5 +0,020 +0,080	6,0	2,5	0,5	-	on request
JSM0304-05	3,0 +0,014 +0,054	4,5	5,0	0,5	✓	3,08 €
JSM0308-04	3,0 +0,020 +0,080	8,0	4,0	0,5	-	4,55 €
JSM0308-05	3,0 +0,020 +0,080	8,0	5,0	0,5	-	3,88 €
JSM0405-04	4,0 +0,020 +0,068	5,5	4,0	0,5	✓	2,51 €
JSM0507-05	5,0 +0,020 +0,068	7,0	5,0	0,5	✓	2,58 €
JSM0608-06	6,0 +0,020 +0,068	8,0	6,0	0,5	✓	3,13 €
JSM0608-10	6,0 +0,020 +0,068	8,0	10,0	0,5	✓	3,34 €
JSM0810-08	8,0 +0,025 +0,083	10,0	8,0	0,5	✓	2,58 €
JSM0810-10	8,0 +0,025 +0,083	10,0	10,0	0,5	✓	3,18 €
JSM0810-12	8,0 +0,025 +0,083	10,0	12,0	0,5	✓	2,36 €
JSM0810-16	8,0 +0,025 +0,083	10,0	16,0	0,5	✓	3,41 €
JSM1012-05	10,0 +0,025 +0,083	12,0	5,0	0,5	✓	2,58 €
JSM1012-08	10,0 +0,025 +0,083	12,0	8,0	0,5	✓	2,63 €
JSM1012-15	10,0 +0,025 +0,083	12,0	15,0	0,5	✓	3,51 €
JSM1012-20	10,0 +0,025 +0,083	12,0	20,0	0,5	✓	3,67 €
JSM1014-16	10,0 +0,025 +0,083	14,0	16,0	0,5	-	3,28 €
JSM1016-10	10,0 +0,025 +0,083	16,0	10,0	0,5	-	3,34 €
JSM1016-16	10,0 +0,025 +0,083	16,0	16,0	0,5	-	3,73 €
JSM1214-08	12,0 +0,032 +0,102	14,0	8,0	0,8	✓	2,85 €
JSM1214-09	12,0 +0,032 +0,102	14,0	9,0	0,8	-	2,85 €
JSM1214-10	12,0 +0,032 +0,102	14,0	10,0	0,8	✓	2,85 €
JSM1214-15	12,0 +0,032 +0,102	14,0	15,0	0,8	✓	3,60 €
JSM1416-10	14,0 +0,032 +0,102	16,0	10,0	0,8	-	3,13 €
JSM1416-15	14,0 +0,032 +0,102	16,0	15,0	0,8	-	3,18 €
JSM1416-25	14,0 +0,032 +0,102	16,0	25,0	0,8	-	3,73 €
JSM1418-18	14,0 +0,032 +0,102	18,0	18,0	0,8	-	3,73 €
JSM1517-12	15,0 +0,032 +0,102	17,0	12,0	0,8	✓	3,67 €
JSM1517-20	15,0 +0,032 +0,102	17,0	20,0	0,8	-	3,51 €
JSM1618-12	16,0 +0,032 +0,102	18,0	12,0	0,8	✓	4,11 €
JSM1618-20	16,0 +0,032 +0,102	18,0	20,0	0,8	✓	4,11 €
JSM1820-20	18,0 +0,032 +0,102	20,0	20,0	0,8	-	4,93 €
JSM2023-20	20,0 +0,040 +0,124	23,0	20,0	0,8	-	4,98 €
JSM2023-25	20,0 +0,040 +0,124	23,0	25,0	0,8	✓	4,87 €
JSM2026-30	20,0 +0,040 +0,124	26,0	30,0	0,8	✓	6,29 €
JSM2427-25	24,0 +0,032 +0,102	27,0	25,0	0,8	-	6,20 €
JSM2528-30	25,0 +0,040 +0,124	28,0	30,0	0,8	✓	8,49 €
JSM2630-20	26,0 +0,040 +0,124	30,0	25,0	0,8	-	5,51 €

*Depending on availability - Dimensions in mm