

Cylindrical reducing sleeve

SteSta

MCL


Steel or **stainless steel**

- **Male/female sleeve**
- Allows 2 rods of different diameters to be joined
- Materials:
 - Galvanised steel
 - 303 Stainless steel



Info.

- Supplied by pack

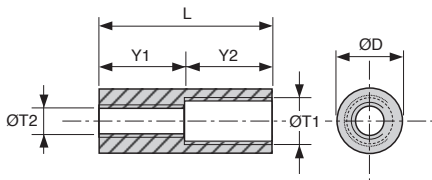

DISCOUNTS

Qty	1+	5+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	ØT1	ØT2	ØD	L	Y1	Y2	Qty per pack	Price each 1 to 4
Steel								
MCL6-8-40/B	M6	M8	13	40	20	20	20	24,89 €
MCL6-10-40/B	M6	M10	16	40	20	20	20	32,82 €
MCL8-10-40/B	M8	M10	16	40	20	20	20	32,82 €
MCL8-12-40/B	M8	M12	16	40	20	20	20	32,82 €
MCL10-12-40/B	M10	M12	16	40	20	20	20	32,82 €
MCL10-16-40/B	M10	M16	22	40	20	20	20	46,91 €
MCL12-16-40/B	M12	M16	22	40	20	20	20	46,91 €
Stainless steel								
MCL6-8-40/SS/B	M6	M8	13	40	20	20	20	56,27 €
MCL6-10-40/SS/B	M6	M10	16	40	20	20	20	74,27 €
MCL8-10-40/SS/B	M8	M10	16	40	20	20	20	74,27 €
MCL8-12-40/SS/B	M8	M12	16	40	20	20	20	74,27 €
MCL10-12-40/SS/B	M10	M12	16	40	20	20	20	74,27 €
MCL10-16-40/SS/B	M10	M16	22	40	20	20	20	137,37 €
MCL12-16-40/SS/B	M12	M16	22	40	20	20	20	137,37 €


Dimensions in mm

- Manicotto cilindrico filettato (con filetto passante interno)
- Ideale per la giunzione di barre filettate
- Materiali:

Acciaio S300PB zincato Zn3-5BL

Inox 303

 - Confezioni da 20 pezzi



acciaio o inox



SCONTI PER QUANTITÀ

N. conf.	1+	5+	20+	50+
Sc.	Prezzo	-5%	-10%	Su richiesta

Codice	filettatura	Qtà per conf.	Stock*		Prezzo unit. per conf. Da 1 a 4	
			Acciaio	inox	Acciaio	inox
MCL4-15/B	-	20	✓	-	5,56 €	-
MCL4-20/B	-	20	✓	-	5,93 €	-
-	MCL5-15/SS/B	20	-	✓	-	20,40 €
MCL5-20/B	-	20	✓	-	4,93 €	-
MCL5-25/B	-	20	✓	-	5,33 €	-
MCL6-10/B	MCL6-10/SS/B	20	✓	✓	7,39 €	24,12 €
MCL6-15/B	-	20	✓	-	4,70 €	-
MCL6-20/B	MCL6-20/SS/B	20	✓	✓	5,14 €	31,62 €
MCL6-25/B	MCL6-25/SS/B	20	✓	✓	6,07 €	37,75 €
MCL6-30/B	MCL6-30/SS/B	20	✓	✓	7,63 €	44,93 €
MCL6-35/B	-	20	✓	-	9,13 €	-
MCL6-40/B	-	20	✓	-	11,27 €	-
MCL6-50/B	-	20	✓	-	16,36 €	-
MCL8-15/B	-	20	✓	-	4,75 €	-
MCL8-20/B	MCL8-20/SS/B	20	✓	✓	5,43 €	36,72 €
MCL8-25/B	MCL8-25/SS/B	20	✓	-	5,49 €	38,81 €
MCL8-30/B	MCL8-30/SS/B	20	✓	✓	6,63 €	47,95 €
MCL8-35/B	MCL8-35/SS/B	20	-	-	10,01 €	58,19 €
MCL8-40/B	MCL8-40/SS/B	20	✓	-	11,37 €	60,24 €
MCL8-50/B	MCL8-50/SS/B	20	✓	✓	16,50 €	73,51 €
MCL10-20/B	MCL10-20/SS/B	20	✓	-	7,39 €	45,95 €
MCL10-25/B	MCL10-25/SS/B	20	-	-	8,08 €	Su richiesta
MCL10-30/B	MCL10-30/SS/B	20	-	-	8,91 €	66,36 €
MCL10-35/B	-	20	-	-	10,65 €	-
MCL10-40/B	MCL10-40/SS/B	20	-	-	11,94 €	88,84 €
MCL10-50/B	MCL10-50/SS/B	20	-	-	19,91 €	100,08 €
MCL10-60/B	-	20	-	-	22,81 €	-
MCL12-20/B	-	20	✓	-	9,00 €	-
MCL12-25/B	-	20	-	-	10,89 €	-
MCL12-30/B	MCL12-30/SS/B	20	✓	-	11,92 €	88,84 €
MCL12-35/B	-	20	-	-	12,87 €	-
MCL12-40/B	MCL12-40/SS/B	20	-	-	14,97 €	102,15 €
MCL12-50/B	MCL12-50/SS/B	20	-	-	21,84 €	122,53 €
MCL12-60/B	-	20	✓	-	26,39 €	-

*Nei limiti delle disponibilità - Dimensioni in mm