

# Cylindrical Master-Plate® glueable insert Ø23

Inox 316L

MSP23


- Glueable stainless steel plate with tapped insert or threaded stud
- Material:  
316L stainless steel

## Applications



- Industrial, transport, building, furnishings

## Info.


- Glue not supplied
- Not supplied individually, contact us for details

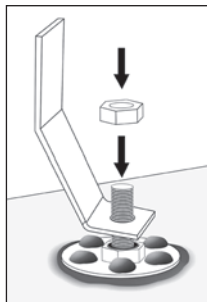


Typical application

  

Tapped

 

Nut

 

Thread

316L stainless steel

316L stainless steel



## DISCOUNTS

Qty	1+	50+	100+	500+
Disc.	List	-10%	-20%	On request

Part number	A	ØD	L	Form	Price each 1 to 49
MSP23T-4-10/SS	23	M4	10	Tapped	6,13 €
MSP23T-5-10/SS	23	M5	10	Tapped	6,33 €
MSP23T-6-10/SS	23	M6	10	Tapped	6,55 €
MSP23E-4-3/SS	23	M4	3,2	Nut	1,93 €
MSP23E-5-4/SS	23	M5	4	Nut	1,97 €
MSP23E-6-5/SS	23	M6	5	Nut	2,24 €
MSP23F-4-16/SS	23	M4	16	Thread	2,05 €
MSP23F-4-20/SS	23	M4	20	Thread	2,07 €
MSP23F-5-12/SS	23	M5	12	Thread	2,07 €
MSP23F-6-25/SS	23	M6	25	Thread	2,26 €

Fax

0 825 88 6000

Service 0,15 € / min  
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

83