

# Cylindrical Master-Plate® glueable insert Ø38

## MSP38

## Inox 316L


- Glueable stainless steel plate with tapped insert or threaded stud
- Material:  
316L stainless steel

### Applications



- Industrial, transport, building, furnishings

### Info.

- Glue not supplied
- Not supplied individually, contact us for details

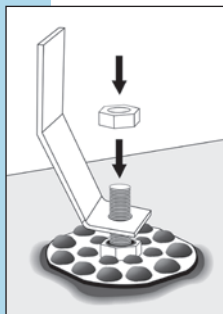

Exemple d'application

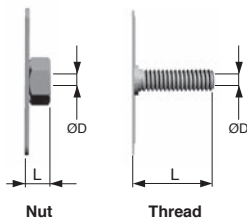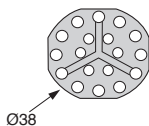

### DISCOUNTS

| Qty   | 1+   | 50+  | 100+ | 500+       |
|-------|------|------|------|------------|
| Disc. | List | -10% | -20% | On request |

| Part number    | ØA | ØD | L   | Form         | Price each<br>1 to 49 |
|----------------|----|----|-----|--------------|-----------------------|
| MSP38EB-8-6/SS | 38 | M8 | 6,5 | Blind tapped | 3,11 €                |
| MSP38E-8-6/SS  | 38 | M8 | 6,5 | Nut          | 3,11 €                |
| MSP38F-6-40/SS | 38 | M6 | 40  | Thread       | 3,11 €                |
| MSP38F-8-40/SS | 38 | M8 | 40  | Thread       | 3,51 €                |

Dimensions in mm