

# Articulated foot with sheet metal base Ø100

## PAMF100

Max load: 15,000N  
Rubber sole in EPDM, blue



- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
  - Base: shiny 304 stainless steel sheet
  - Thread: 304 stainless steel, supplied without nut
  - Sole: EPDM blue

### Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

### Advantages

- Hygienic special pad for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

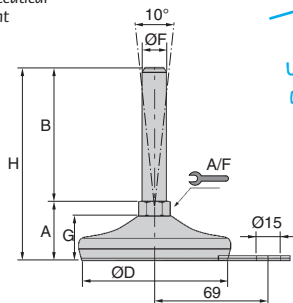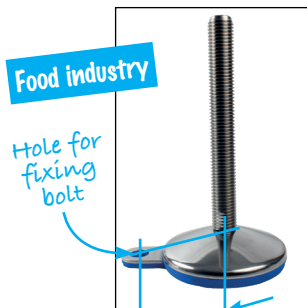

### DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price	-5%	-10%	-10%	-15%	On request

References	Threading		B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
	ØD	ØF							
PAMF100-16-100/EB	100	M16	100	39.5	13	30	139.5	15000	53,37€
PAMF100-16-150/EB	100	M16	150	39.5	13	30	189.5	15000	54,99€
PAMF100-16-200/EB	100	M16	200	39.5	13	30	239.5	15000	58,69€
PAMF100-20-100/EB	100	M20	100	43.0	17	30	143.0	15000	56,55€
PAMF100-20-150/EB	100	M20	150	43.0	17	30	193.0	15000	59,76€
PAMF100-20-200/EB	100	M20	200	43.0	17	30	243.0	15000	63,46€


\* Depending on availability - Dimensions in mm

## Our other products




TB\_ECO

Bevel gear - Steel  
C43, 3:1

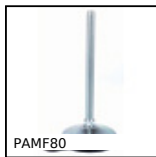

PAMF80

Articulated fixable  
foot with pressed  
base, Ø 80

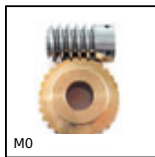

M0

Wheel, Bronze



PCS625S

Chain sprocket -  
Stainless steel,  
15.875mm (DIN  
08B-1)



VEL

Self-gripping cable  
strip,



INS

Self tapping insert,  
Steel



BLHB30

Right angled gearbox,  
up to 4.47 Nm



RTE

Rotex®, flexible, cast  
iron



PX\_PO

Carry handle,  
standard




GE1006

Flexible toggle latch,  
Hooks into a slot



HK

Linear ball slide -  
Stainless steel balls,  
Manual locking clamp

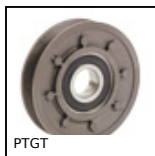

PTGT

Tensioner pulley, For  
V belts

## Complementary products



PTA50ssEB

Articulated foot with  
sheet metal base,  
Articulated foot



PTA80ssEB

Articulated foot with  
sheet metal base,  
Articulated foot



PTA100ssEB

Articulated foot with  
sheet metal base,  
Articulated foot



PAMF80EB

Articulated foot with  
sheet metal base,  
Articulated foot