



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PAMF80

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request


Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

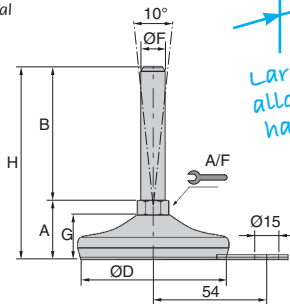


DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc. Price		-5%	-10%	-15%	On request

Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PAMF80-12-100/EB	80	M12	100	35	14	25	135	10000	36,75 €
PAMF80-12-150/EB	80	M12	150	35	14	25	185	10000	38,83 €
PAMF80-16-75/EB	80	M16	75	35	13	25	110	10000	37,24 €
PAMF80-16-125/EB	80	M16	125	35	13	25	160	10000	39,90 €
PAMF80-16-175/EB	80	M16	175	35	13	25	210	10000	42,53 €
PAMF80-20-100/EB	80	M20	100	38	17	25	138	10000	42,53 €
PAMF80-20-150/EB	80	M20	150	38	17	25	188	10000	45,16 €
PAMF80-20-200/EB	80	M20	200	38	17	25	238	10000	49,11 €

*Within the limits of available stock - Dimensions in mm

Our other products

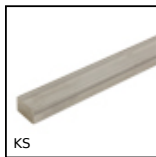

Key, Stainless steel - Keystock



Roller for aluminium profile, Fixing kit for roller concentric



Closing system, Easily adjustable lock



Single and dual output gearboxes, Up to 87,3Nm



Wheel, Integrated bearing



Captive C washer, Slotted flat headed shoulder screw



Indexing plunger, Weldable - Steel



Locating bolt support bracket, Mounting holes at 90° to locating bolt



Support base, Bipod support element with cross support



Friction torque limiter, 190 to 1800 Nm



Hypoid gearbox - Stainless steel, up to 350 Nm



Bevel gear - Steel 60C40, 2:1

Complementary products



Articulated foot with sheet metal base, Articulated foot



Articulated foot with sheet metal base, Articulated foot



Articulated foot with sheet metal base, Articulated foot



Articulated foot with sheet metal base, Articulated foot