

Piede fisso



PFC


Carico max: fino a 3 150N

- **Piede di livellamento per piccoli elementi**

- **Materiali:**

Stelo: acciaio o inox 304

Piede: gomma NBR durezza 70 shore

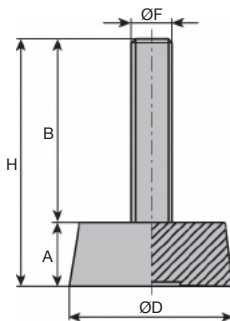

SCONTI PER QTÀ

Qtà	1+	50+	100+
Sc.	Prezzo	-5%	Su richiesta

Codice	ØD	ØF	A	H	B	Carico max (N)	Stock*	Prezzo unit. Da 1 a 49
In acciaio								
PFC40-8	40	M8	16	41	25	1800	✓	3,48 €
PFC40-10	40	M10	16	41	25	2250	✓	4,09 €
PFC40-12	40	M12	16	41	25	3150	✓	4,75 €
In inox								
PFC40-8/SS	40	M8	16	41	25	1800	✓	4,09 €
PFC40-10/SS	40	M10	16	41	25	2250	✓	4,44 €
PFC40-12/SS	40	M12	16	41	25	3150	✓	6,04 €

*Nei limiti delle disponibilità - Dimensioni in mm