

Piede fissabile con snodo Ø123




PR125

Carico fino a 35 000N

- **Piede di livellamento**
- Suola antiscivolo in gomma NBR 70 shore
- Base in poliammide nera rinforzata con fibre di vetro
- Stelo in acciaio zincato o inox 304
- Consegnata senza dado

Con soletta antiscivolo

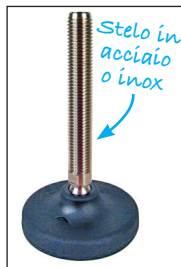

Vantaggi


- Lo stelo a snodo permette l'auto-allineamento a pavimento
- La soletta conferisce elasticità e aderenza

Accessori

- PR125-ENT

Info.

- In caso di vibrazioni, i carichi statici indicati saranno più deboli

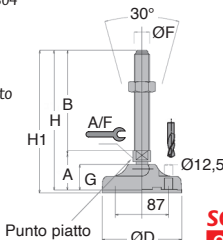

SCONTI PER QUANTITÀ

Qtà	1+	20+	50+
Sc.	Prezzo	-10%	Su richiesta

Codice	Filettatura			A	A/F	G	H	H1	Carico statico (N)	Stock*	Prezzo unit. da 1 a 19
	ØD	ØF	B								
Stelo in acciaio											
PR125-16-75	123	M16	75	57	20	37	132	133	35000	✓	21,89 €
PR125-16-150	123	M16	150	57	20	37	207	208	35000	✓	25,75 €
PR125-16-225	123	M16	225	57	20	37	282	285	35000	✓	30,10 €
PR125-20-125	123	M20	125	57	20	37	182	185	35000	✓	21,77 €
PR125-20-200	123	M20	200	57	20	37	257	260	35000	✓	25,42 €
PR125-20-250	123	M20	250	57	20	37	307	310	35000	✓	29,87 €
PR125-24-125	123	M24	125	57	20	37	182	185	35000	✓	21,77 €
PR125-24-200	123	M24	200	57	20	37	257	260	35000	✓	25,42 €
PR125-24-250	123	M24	250	57	20	37	307	310	35000	✓	29,87 €
PR125-30-125	123	M30	125	58	26	37	183	186	35000	✓	23,38 €
PR125-30-200	123	M30	200	58	26	37	258	261	35000	✓	27,97 €
PR125-30-250	123	M30	250	58	26	37	308	311	35000	-	31,13 €
Stelo inox											
PR125-16-75/SS	123	M16	75	57	20	37	132	135	35000	-	37,74 €
PR125-16-150/SS	123	M16	150	57	20	37	207	210	35000	✓	48,48 €
PR125-16-225/SS	123	M16	225	57	20	37	282	285	35000	-	61,20 €
PR125-20-125/SS	123	M20	125	57	20	37	182	185	35000	✓	44,91 €
PR125-20-200/SS	123	M20	200	57	20	37	257	260	35000	✓	57,38 €
PR125-20-250/SS	123	M20	250	57	20	37	307	310	35000	-	65,97 €
PR125-24-125/SS	123	M24	125	57	20	37	182	185	35000	-	44,91 €
PR125-24-200/SS	123	M24	200	57	20	37	257	260	35000	-	51,18 €
PR125-24-250/SS	123	M24	250	57	20	37	307	310	35000	-	65,97 €
PR125-30-125/SS	123	M30	125	58	26	37	183	186	35000	-	50,96 €
PR125-30-200/SS	123	M30	200	58	26	37	258	261	35000	-	65,06 €
PR125-30-250/SS	123	M30	250	58	26	37	308	311	35000	-	74,14 €

*Nei limiti delle disponibilità - Dimensioni in mm

Extension for articulated foot Ø123

For articulated foot PR125


PR125

Extension with mounting holes for articulated feet PR125


- Material
Polyamide
- Delivered without anti-slip rubber pad
- Suitable for any type of floor

Advantages


- Easily compensates for large differences in floor level

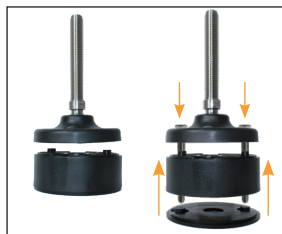

Assembly example
(screws not included)

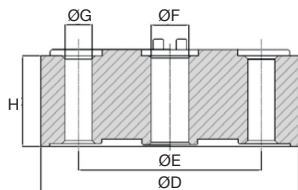

Application example

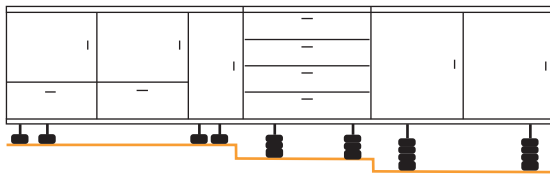

DISCOUNTS

Qty	1+	20+	50+
Disc.	List -10%	On request	

Part number	ØD	ØE	H	ØG	ØF	Static load (N)	Stock*	Price each 1 à 19
PR125-ENT	123	87	43	13	18	35000	-	13,44 €

*Dans la limite du disponible - Dimensions en mm