

# Conical flexible shaft handle Ø20

New

## PSPE20

For shafts Ø6 to Ø12

### Conical handle


- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:  
Black PVC

### Assembly

- Fit using a mallet, no adhesive required



NUOVO!

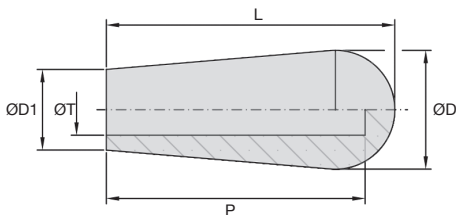

### DISCOUNTS

| Qty   | 1+   | 60+ | 100+ | 200+       |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number  | ØD | ØD1 | ØT | L  | P  | Weight (g) | Price each<br>1 to 59 |
|--------------|----|-----|----|----|----|------------|-----------------------|
| PSPE20-43-6  | 20 | 14  | 6  | 43 | 40 | 11         | 1,78 €                |
| PSPE20-43-7  | 20 | 14  | 7  | 43 | 40 | 10         | 1,68 €                |
| PSPE20-43-8  | 20 | 14  | 8  | 43 | 40 | 10         | 1,62 €                |
| PSPE20-43-10 | 20 | 14  | 10 | 43 | 40 | 9          | 1,56 €                |
| PSPE20-43-12 | 20 | 14  | 12 | 43 | 40 | 8          | 1,50 €                |

Dimensions in mm

**New**

# Conical flexible shaft handle Ø22

## For shafts Ø7 to Ø14


## PSPE22

### Conical handle

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:  
Black PVC

### Assembly

- Fit using a mallet, no adhesive required

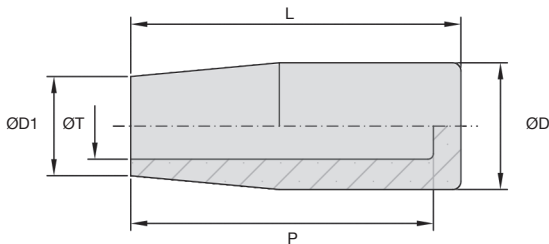**NUOVO !**

### DISCOUNTS

| Qty   | 1+   | 60+ | 100+ | 200+       |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number  | ØD | ØD1 | ØT | L  | P  | Weight (g) | Price each 1 to 59 |
|--------------|----|-----|----|----|----|------------|--------------------|
| PSPE22-60-7  | 22 | 17  | 7  | 60 | 58 | 24         | 2,82 €             |
| PSPE22-60-8  | 22 | 17  | 8  | 60 | 58 | 23         | 2,63 €             |
| PSPE22-60-9  | 22 | 17  | 9  | 60 | 58 | 23         | 2,54 €             |
| PSPE22-60-10 | 22 | 17  | 10 | 60 | 58 | 22         | 2,48 €             |
| PSPE22-60-12 | 22 | 17  | 12 | 60 | 58 | 21         | 2,36 €             |
| PSPE22-60-14 | 22 | 17  | 14 | 60 | 58 | 20         | 2,30 €             |

Dimensions in mm

# Flexible tube handle

New Stock

## PSPD18

For tubes Ø12 to Ø22

### Knurled cylindrical handle

- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:  
Black PVC

### Assembly


- Fit using a mallet, no adhesive required

### Advantages


- Ergonomic handle for excellent grip



NUOVO!

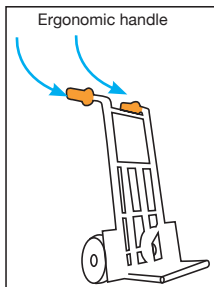

Typical application

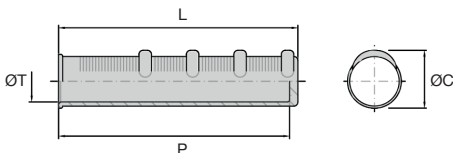

### DISCOUNTS

| Qty   | 1+   | 60+ | 100+ | 200+       |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number    | L   | ØT | ØC | P   | Weight (g) | Stock* | Price each 1 to 59 |
|----------------|-----|----|----|-----|------------|--------|--------------------|
| PSPD18-118-12  | 118 | 12 | 28 | 113 | 52         | ✓      | 4,31 €             |
| PSPD18-118-14  | 118 | 14 | 28 | 113 | 45         | -      | 4,00 €             |
| PSPD18-118-16  | 118 | 16 | 28 | 113 | 40         | ✓      | 3,61 €             |
| PSPD18-118-18  | 118 | 18 | 28 | 113 | 35         | ✓      | 3,24 €             |
| PSPD18-118-20  | 118 | 20 | 28 | 113 | 28         | ✓      | 2,48 €             |
| PSPD18-118-21  | 118 | 21 | 28 | 113 | 26         | -      | 2,30 €             |
| PSPD18-118-22  | 118 | 22 | 28 | 113 | 22         | ✓      | 2,11 €             |
| PSPD18-118-22L | 118 | 22 | 28 | 113 | 19         | -      | 2,17 €             |

\*Depending on availability - Dimensions in mm

## Knurled cylindrical handle



- Smooth blind hole
- Working T°: 0°C to +70°C
- Material:  
Black PVC

## Assembly

- Fit using a mallet, no adhesive required

## Advantages

- Ergonomic handle for excellent grip

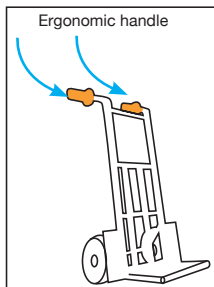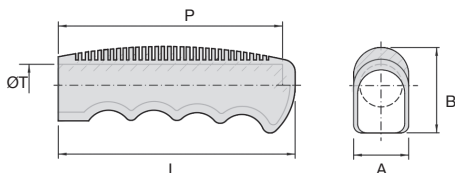

Typical application

## DISCOUNTS

| Qty   | 1+   | 60+ | 100+ | 200+       |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number   | L   | A  | B  | ØT | P   | Weight (g) | Stock* | Price each 1 to 59 |
|---------------|-----|----|----|----|-----|------------|--------|--------------------|
| PSPD40-112-18 | 112 | 26 | 40 | 18 | 106 | 49         | ✓      | 4,68 €             |
| PSPD40-112-22 | 112 | 26 | 40 | 22 | 106 | 47         | ✓      | 4,68 €             |

\*Depending on availability - Dimensions in mm

# Flexible tube handle



## PSPT

For Ø18 - Ø33 tubes

- Tube handle with collar
- Smooth interior
- Material:  
Black PVC

### Assembly


- Fit using a mallet,  
no adhesive required

### Advantages


- Resists oil, shocks and low  
temperatures



**NUOVO !**

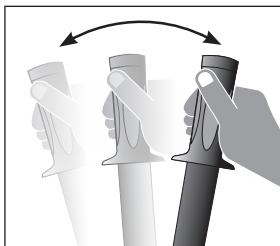

Typical application

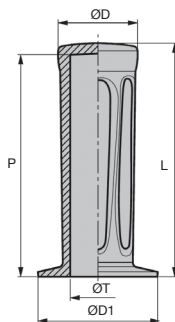

### DISCOUNTS

| Qty   | 1+   | 60+ | 100+ | 200+       |
|-------|------|-----|------|------------|
| Disc. | List | -5% | -10% | On request |

| Part number | Tube<br>ØT | L   | ØD | ØD1 | P   | Weight<br>(g) | Stock* | Price each<br>1 to 59 |
|-------------|------------|-----|----|-----|-----|---------------|--------|-----------------------|
| PSPT18-115  | 18-19      | 115 | 31 | 44  | 110 | 62            | ✓      | 3,22 €                |
| PSPT20-115  | 20-21      | 115 | 31 | 44  | 110 | 56            | ✓      | 2,84 €                |
| PSPT22-115  | 22-23      | 115 | 31 | 44  | 110 | 46            | ✓      | 2,47 €                |
| PSPT24-125  | 24-25      | 125 | 36 | 49  | 120 | 72            | ✓      | 3,67 €                |
| PSPT26-125  | 26         | 125 | 36 | 49  | 120 | 60            | ✓      | 3,22 €                |
| PSPT27-125  | 27-28      | 125 | 36 | 49  | 120 | 50            | ✓      | 3,10 €                |
| PSPT29-125  | 29         | 125 | 36 | 49  | 120 | 50            | ✓      | 3,10 €                |
| PSPT30-130  | 30         | 130 | 42 | 51  | 125 | 92            | ✓      | 3,67 €                |
| PSPT33-130  | 33         | 130 | 42 | 51  | 125 | 74            | ✓      | 3,28 €                |

\*Depending on availability - Dimensions in mm