

# Drive sprocket for plate chain

## PT880


## For chain range 880 TAB

- For driving CAP880T chains
- With bore and keyway
- Materials:
  - Reinforced polyamide
  - Stainless steel screws
- Operating temp.: -10°C to +120°C
- For dimensions and bore tolerances, please refer to technical pages


### Advantage

- Two part design facilitates easy assembly

**Easy assembly**

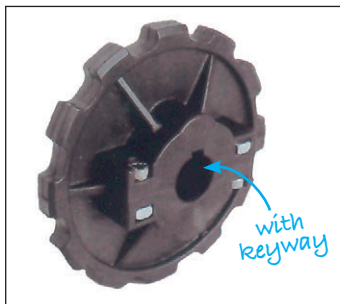

Two part design

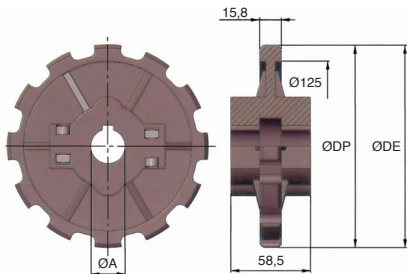

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	No. of teeth	ØDE	ØDP	Bore ØA	Weight (kg)	Price each 1 to 4
PT880-12-25	12	147,2	147,21	25	0,39	29,36 €
PT880-12-30	12	147,2	147,21	30	0,39	29,36 €
PT880-12-35	12	147,2	147,21	35	0,39	29,36 €
PT880-12-40	12	147,2	147,21	40	0,39	29,36 €

Dimensions in mm