

Articulated foot with sheet metal base Ø100

PTA100SS/EB

Max load: 15,000N
Rubber sole in EPDM, blue

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

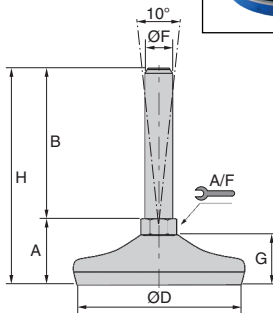

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request


Part N°	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA100-16-100/SS/EB	100	M16	100	39.5	13	30	139.5	15000	45,66€
PTA100-16-150/SS/EB	100	M16	150	39.5	13	30	189.5	15000	47,28€
PTA100-16-200/SS/EB	100	M16	200	39.5	13	30	239.5	15000	50,98€
PTA100-20-100/SS/EB	100	M20	100	43.0	17	30	143.0	15000	48,84€
PTA100-20-150/SS/EB	100	M20	150	43.0	17	30	193.0	15000	51,99€
PTA100-20-200/SS/EB	100	M20	200	43.0	17	30	243.0	15000	55,69€
PTA100-24-100/SS/EB	100	M24	100	44.0	20	30	144.0	15000	52,54€
PTA100-24-150/SS/EB	100	M24	150	44.0	20	30	194.0	15000	54,13€

* Depending on availability - Dimensions in mm

Our other products



NDS20
Double cross clamp,
Parallel

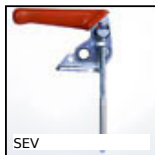

SEV
Clamp, Vertical Latch
Clamp - steel



PRES
Accessories for
PRES-3HR and
PRES-4HR presses,
Tool holder



NSU
Sensor support,
Universal 90° support
clamp



V3RA_PT
Hand wheel,
Polyamide



P55
Worm and wheel
gearbox, up to 57 Nm



RAM30
Manual gearbox,
Bevel



DBL805
Idler, Range 805




MEB
Moulded plastic bevel
gear (nylon), 1:1



PRF_BM
Floor anchor, Central
base fixation



ECF
Well nut, Elastomer

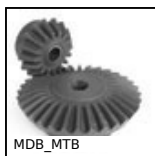

MDB_MTB
Moulded plastic bevel
gear (nylon), 2:1

Complementary products



PTA50ssEB
Articulated foot with
sheet metal base,
Articulated foot



PTA80ssEB
Articulated foot with
sheet metal base,
Articulated foot



PAMF80EB
Articulated foot with
sheet metal base,
Articulated foot



PAMF100EB
Articulated foot with
sheet metal base,
Articulated foot