

- Idler pulley


- Material:

PA6 reinforced with 30% fibreglass

Steel bearing

- Max speed 5,000 RPM

(Except for PTGP30 + PTGP32 = 9,000 RPM)

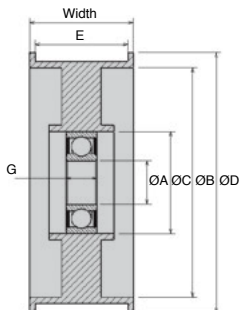

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	ØD	Width		Bearing	ØC	ØA	E	G	For shaft	Price each
		L	ØB							
PTGP30-9-8	40	13,2	30	608 2RS	20	8	9,2	7	AXTR-M8	12,54 €
PTGP32-13-8	42	17,2	32	608 2RS	22	8	13,2	7	AXTR-M8	12,73 €
PTGP50-18-17	62	22,5	50	6203 2RS	38	17	18,3	12	AXTR-M12	13,96 €
PTGP50-20-17	62	26	50	6203 2RS	38	17	20,3	12	AXTR-M12	13,96 €
PTGP75-25-17	87	29,5	75	6203 2RS	38	17	25,3	12	AXTR-M12	16,59 €
PTGP75-31-17	87	35,5	75	6203 2RS	38	17	31,3	12	AXTR-M12	19,49 €
PTGP75-31-17D	87	35,5	75	6203 2RS	38	17	31,3	24	AXTR-M12	25,19 €
PTGP90-18-17	102	22,5	90	6203 2RS	38	17	18,3	12	AXTR-M12	28,09 €
PTGP90-31-17	102	35,5	90	6203 2RS	38	17	31,3	12	AXTR-M12	28,34 €
PTGP90-31-17D	102	35,5	90	6203 2RS	38	17	31,3	24	AXTR-M12	28,83 €
PTGP90-36-17D	102	40,5	90	6203 2RS	38	17	36,3	24	AXTR-M12	29,09 €
PTGP115-36-17	127	30,5	115	6203 2RS	38	17	26,6	12	AXTR-M12	34,09 €

Dimensions in mm