


- Idler pulley
- Material:  
PA6 reinforced with 30% fibreglass  
steel bearing
- Max speed 5,000 RPM

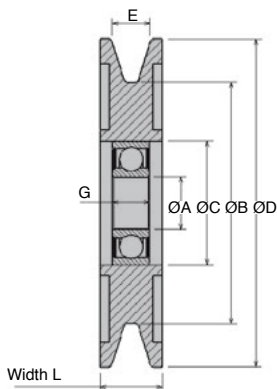

## DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	For V belt	ØD	Width L	ØB	Bearing	C	ØA	E	G	For shaft	Price each 1 to 9
PTGT49-13-17	A	76	18	49	6203 2RS	38	17	13,3	12	AXTR-M12	15,02 €
PTGT75-13-17	SPA	102	18	75	6203 2RS	38	17	12,8	12	AXTR-M12	17,24 €
PTGT96-15-17	XPB	127	21	96	6203 2RS	38	17	15,8	12	AXTR-M12	24,75 €

Dimensions en mm