

Self-aligning radial ball bearing

New

Q1
Q2

Steel

- Self aligning bearing that is unaffected by any errors in alignment
- Static and dynamic loads are radial loads
- Materials:
Rings and balls: steel
ETN9: Polyamide cage
ACC: Steel cage




DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List	-10%	-15%	-20%	-30%	On request

Part number	Ød	ØD1	B	Load (kN)		Speed (rpm)		Weight (kg)	Price each 1 to 5
				Dynamic (C)	Static (Co)	Grease	Oil		
Q126-ETN9	6	19	6	2,460	0,470	34425	40500	0,009	3,69 €
Q1200-ETN9	10	30	9	5,420	1,160	27540	32400	0,034	3,66 €
Q1201-ETN9	12	32	10	6,120	1,400	24480	28800	0,040	3,84 €
Q2201-ETN9	12	32	14	8,350	1,860	22950	27000	0,053	4,60 €
Q1202-ETN9	15	35	11	7,260	1,720	21420	25200	0,049	3,88 €
Q2202-ETN9	15	35	14	8,540	2,000	19890	23400	0,060	4,76 €
Q1203-ETN9	17	40	12	8,660	2,160	18360	21600	0,073	4,91 €
Q2203-ETN9	17	40	16	10,390	2,500	18360	21600	0,088	5,07 €
Q1204-ETN9	20	47	14	12,450	3,330	15300	18000	0,120	5,03 €
Q2204-ETN9	20	47	18	16,460	4,070	15300	18000	0,140	6,32 €
Q1205-ACC	25	52	15	14,010	3,920	13770	16200	0,140	5,97 €
Q2205-ETN9	25	52	18	16,460	4,310	13770	16200	0,160	6,71 €
Q1305-ETN9	25	62	17	18,620	5,290	11475	13500	0,260	9,49 €
Q2305-ETN9	25	62	24	26,460	6,960	12240	14400	0,340	12,69 €
Q1206-ETN9	30	62	16	15,290	4,560	11475	13500	0,220	7,69 €
Q2206-ETN9	30	62	20	23,320	6,570	11475	13500	0,260	10,59 €
Q1306-ETN9	30	72	19	22,050	6,660	9945	11700	0,390	11,46 €
Q2306-ETN9	30	72	27	30,580	8,620	9945	11700	0,500	18,55 €
Q1207-ETN9	35	72	17	18,620	5,880	9945	11700	0,320	10,43 €
Q2207-ETN9	35	72	23	30,090	8,620	9180	10800	0,400	11,85 €
Q1307-ACC	35	80	21	25,970	8,330	8415	9900	0,510	14,67 €
Q2307-ACC	35	80	31	38,910	10,980	9180	10800	0,680	19,31 €

Dimensions in mm

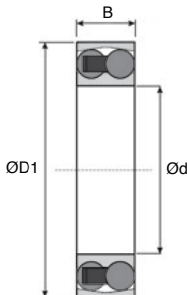

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List	-10%	-15%	-20%	-30%	On request

Part number	Ød	ØD1	B	Load (kN)		Speed (rpm)		Weight (kg)	Price each
				Dynamic (C)	Static (Co)	lubricant Grease	Oil		
Q1208-ETN9	40	80	18	19,500	6,810	8415	9900	0,420	12,96 €
Q2208-ETN9	40	80	23	31,260	9,800	8415	9900	0,510	13,68 €
Q2308-ACC	40	90	33	52,920	15,680	7650	9000	0,930	26,33 €
Q1209-ACC	45	85	19	22,440	7,640	8415	9900	0,470	13,41 €
Q2209-ACC	45	85	23	31,850	10,390	7650	9000	0,550	16,50 €
Q2309-ACC	45	100	36	62,430	18,910	6885	8100	1,250	39,78 €
Q1210-ACC	50	90	20	25,970	8,970	7650	9000	0,530	15,12 €
Q2210-ACC	50	90	23	33,120	10,980	7268	8550	0,600	18,67 €
Q1310-ETN9	50	110	27	42,730	13,720	6120	7200	1,200	32,04 €
Q2310-ACC	50	110	40	62,430	19,600	7268	8550	1,650	48,74 €
Q1211-ETN9	55	100	21	27,050	10,390	6885	8100	0,710	20,16 €
Q2211-ACC	55	100	25	38,220	13,130	6503	7650	0,810	26,21 €
Q1311-ACC	55	120	29	49,690	17,640	5738	6750	1,600	36,73 €
Q2311-ACC	55	120	43	74,580	23,520	5738	6750	2,100	94,70 €
Q1212-ACC	60	110	22	30,580	11,960	6503	7650	0,900	23,01 €
Q2212-ACC	60	110	28	47,820	16,660	6120	7200	1,100	32,96 €
Q1312-ACC	60	130	31	57,330	21,560	4820	5670	1,950	45,08 €
Q2312-ACC	60	130	46	85,360	27,930	5355	6300	2,600	97,52 €
Q1213-ACC	65	120	23	34,400	13,720	5355	6300	1,150	27,55 €
Q2213-ACC	65	120	31	56,060	19,600	5355	6300	1,450	39,82 €
Q2215-ACC	75	130	31	57,330	21,560	4820	5670	1,600	50,45 €
Q2216-ACC	80	140	33	63,700	24,990	4590	5400	2,000	55,33 €
Q2218-ACC	90	160	40	68,800	27,930	4055	4770	3,400	110,10 €

Dimensions in mm