

# RPP timing belt



## Pitch RPP5

Chloroprene rubber belt  
with glass fibre tension members


- To be used with HTD5M pulley
- Pitch 5mm
- Efficiency: up to 98%
- Materials:  
Chloroprene rubber reinforced with glass fibres  
nylon protective film

### Advantages

- Shock-resistant
- The RPP parabolic tooth profile gives a higher torque capability and greater resistance to tooth jump

### Accessories

- Pulleys HTD5M
- Belt tension rollers GTC

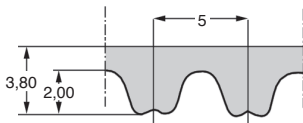

### DISCOUNTS

Qty	1+	6+	20+
Disc. List	-7%	-7%	On request

Part number	Length	N°. of teeth	Stock*	Stock*	Price each 1 to 5 for a width of		
			9mm	15mm	9mm	15mm	25mm
RPP5/180	180	36	✓	✓	6,74 €	11,05 €	-
RPP5/225	225	45	✓	✓	6,88 €	11,05 €	-
RPP5/235	235	47	✓	-	6,88 €	11,24 €	16,10 €
RPP5/245	245	49	✓	-	7,05 €	11,24 €	16,10 €
RPP5/255	255	51	✓	✓	7,29 €	11,41 €	16,95 €
RPP5/265	265	53	-	-	7,29 €	11,41 €	17,45 €
RPP5/270	270	54	✓	✓	7,29 €	11,59 €	-
RPP5/280	280	56	✓	✓	7,42 €	11,59 €	17,63 €
RPP5/285	285	57	✓	-	7,42 €	11,59 €	17,63 €
RPP5/295	295	59	✓	✓	7,42 €	11,59 €	17,63 €
RPP5/300	300	60	✓	✓	7,60 €	11,59 €	17,82 €
RPP5/305	305	61	✓	✓	7,60 €	11,74 €	17,82 €
RPP5/325	325	65	✓	✓	7,60 €	11,95 €	-
RPP5/345	345	69	✓	✓	7,78 €	12,46 €	18,68 €
RPP5/350	350	70	✓	✓	7,78 €	12,46 €	18,68 €
RPP5/375	375	75	✓	✓	7,92 €	12,82 €	19,18 €
RPP5/400	400	80	✓	✓	8,27 €	12,97 €	19,72 €
RPP5/420	420	84	✓	✓	8,27 €	13,13 €	19,91 €
RPP5/425	425	85	-	-	8,47 €	13,50 €	20,41 €
RPP5/450	450	90	✓	✓	8,63 €	13,82 €	20,76 €
RPP5/455	455	91	✓	✓	8,63 €	13,82 €	20,76 €
RPP5/460	460	92	-	✓	8,63 €	13,82 €	-
RPP5/465	465	93	-	✓	8,63 €	14,00 €	20,95 €
RPP5/475	475	95	-	✓	8,79 €	14,00 €	21,14 €
RPP5/500	500	100	✓	✓	8,99 €	14,55 €	21,63 €

\*Depending on availability - Dimensions in mm

Part number	Length	N°. of teeth	Stock*	Stock*	Price each 1 to 5 for a width of		
			9mm	15mm	9mm	15mm	25mm
RPP5/525	525	105	-	✓	9,15 €	14,71 €	21,98 €
RPP5/535	535	107	-	✓	9,51 €	14,88 €	22,35 €
RPP5/565	565	113	-	✓	9,51 €	15,23 €	23,22 €
RPP5/575	575	115	✓	✓	9,65 €	15,23 €	23,22 €
RPP5/580	580	116	-	✓	9,65 €	15,41 €	-
RPP5/600	600	120	-	-	9,86 €	15,73 €	23,72 €
RPP5/610	610	122	-	✓	10,01 €	15,90 €	24,08 €
RPP5/615	615	123	-	-	10,18 €	16,10 €	-
RPP5/635	635	127	-	-	10,18 €	16,10 €	24,58 €
RPP5/640	640	128	-	-	10,37 €	16,59 €	24,77 €
RPP5/670	670	134	✓	-	10,56 €	16,78 €	25,26 €
RPP5/675	675	135	-	-	10,56 €	16,78 €	25,26 €
RPP5/700	700	140	-	-	10,91 €	17,31 €	26,14 €
RPP5/705	705	141	-	-	10,91 €	17,31 €	-
RPP5/710	710	142	-	-	10,91 €	17,45 €	26,14 €
RPP5/725	725	145	-	-	11,05 €	17,66 €	26,48 €
RPP5/740	740	148	-	-	11,24 €	17,82 €	26,68 €
RPP5/750	750	150	-	✓	11,24 €	17,82 €	26,86 €
RPP5/755	755	151	✓	-	11,24 €	17,82 €	26,86 €
RPP5/800	800	160	-	✓	11,59 €	18,51 €	27,86 €
RPP5/835	835	167	✓	✓	11,74 €	18,87 €	28,40 €
RPP5/850	850	170	✓	✓	12,09 €	19,18 €	28,93 €
RPP5/890	890	178	-	-	12,46 €	19,72 €	29,80 €
RPP5/900	900	180	-	-	12,46 €	19,91 €	29,94 €
RPP5/935	935	187	-	✓	12,82 €	20,26 €	30,50 €
RPP5/940	940	188	-	-	12,82 €	20,41 €	30,98 €
RPP5/950	950	190	-	-	12,97 €	20,59 €	31,18 €
RPP5/980	980	196	-	-	13,13 €	20,95 €	31,52 €
RPP5/1000	1000	200	✓	-	13,50 €	21,46 €	32,21 €
RPP5/1025	1025	205	✓	-	13,82 €	21,63 €	-
RPP5/1050	1050	210	-	-	14,00 €	21,98 €	33,26 €
RPP5/1100	1100	220	-	-	14,36 €	22,54 €	34,48 €
RPP5/1125	1125	225	✓	✓	14,71 €	23,01 €	35,16 €
RPP5/1135	1135	227	-	-	14,79 €	23,54 €	35,84 €
RPP5/1195	1195	239	✓	-	14,88 €	24,22 €	-
RPP5/1200	1200	240	-	✓	15,23 €	24,58 €	36,72 €
RPP5/1240	1240	248	-	✓	15,41 €	24,77 €	37,25 €
RPP5/1270	1270	254	✓	-	15,73 €	24,77 €	37,77 €
RPP5/1420	1420	284	✓	✓	16,95 €	27,03 €	40,88 €
RPP5/1595	1595	319	-	-	18,51 €	29,44 €	44,51 €
RPP5/1690	1690	338	✓	✓	19,05 €	30,50 €	45,74 €
RPP5/1790	1790	358	-	✓	20,26 €	32,03 €	48,51 €
RPP5/1800	1800	360	-	✓	20,41 €	32,21 €	48,51 €
RPP5/1870	1870	374	-	-	20,95 €	33,07 €	-
RPP5/1895	1895	379	-	-	21,26 €	33,61 €	50,60 €
RPP5/1945	1945	389	-	-	21,46 €	33,94 €	-
RPP5/2000	2000	400	✓	-	21,98 €	34,97 €	52,83 €
RPP5/2250	2250	450	✓	✓	24,58 €	38,62 €	62,74 €
RPP5/2525	2525	505	✓	✓	26,68 €	42,07 €	63,59 €

\*Depending on availability - Dimensions in mm