


Inox

Passo  
4mm

- Passo 4mm
- diam. rullo 2.50mm
- Materiale:  
Inox 303

### Accessorio

- Catena codice SUA-4

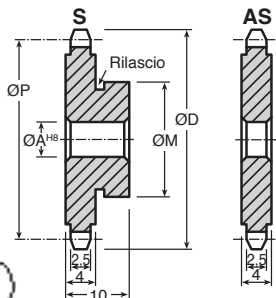

Il più piccolo

### SCONTI PER QUANTITÀ

Qtà	1+	6+	20+	50+
Sc. Prezzo	-5%	-10%	Su richiesta	

Codice	Denti Z	ØP	ØD	ØM	ØA	Rilascio Ø x larghezza	Prezzo unit. da 1 a 5	
							S	AS
S4-10	10	12,94	14,71	12	4	8,00 x 2,5	11,97 €	
S4-11	11	14,20	16,02	12	4	8,00 x 2,5	12,72 €	
S4-12	12	15,45	17,32	12	4	8,00 x 2,5	13,36 €	
S4-13	13	16,71	18,62	12	4	9,05 x 2,5	14,03 €	
S4-14	14	17,97	19,92	12	4	10,33 x 2,5	15,21 €	
S4-15	15	19,23	21,21	12	4	11,60 x 2,5	15,59 €	
S4-16	16	20,50	22,50	12	4	-	16,56 €	
S4-17	17	21,76	23,79	12	4	-	17,93 €	
S4-18	18	23,06	25,08	12	4	-	18,72 €	
S4-19	19	24,29	26,37	12	4	-	19,56 €	
S4-20	20	25,57	27,65	15	5	-	20,47 €	
S4-21	21	26,83	28,94	15	5	-	21,33 €	
S4-23	23	29,37	31,50	15	5	-	22,22 €	
S4-25	25	31,91	34,06	15	5	-	23,09 €	
S4-27	27	34,45	36,62	15	5	-	25,18 €	
S4-30	30	38,26	40,45	15	5	-	28,11 €	
S4-33	33	42,08	44,29	15	5	-	29,62 €	
S4-35	35	44,62	46,84	15	5	-	30,47 €	
S4-36	36	45,89	48,12	15	5	-	31,30 €	
S4-38	38	48,43	50,67	15	5	-	31,52 €	
S4-40	40	50,98	53,22	20	6	-	31,76 €	
S4-42	42	53,52	55,77	20	6	-	31,88 €	
S4-44	44	56,07	58,32	20	6	-	32,17 €	
S4-48	48	61,12	63,42	20	6	-	32,47 €	
S4-50	50	63,66	65,98	20	6	-	32,77 €	
S4-60	60	76,39	78,72	20	6	-	34,06 €	
S4-80	80	101,86	104,20	20	6	-	105,59 €	

Su richiesta

Dimensioni in mm