

## TC1RP

### With 180° guide

**- Tensioner for single chain**

**- Materials:**

Housing: steel with corrosion proof epoxy finish

 

Profile: Green HD1000 polyethylene

Machine column: Black HD500 polyethylene



Screws and springs: stainless steel 304L

### Adjustment

- Tension pressure can be reduced by freeing the springs, see instruction sheet

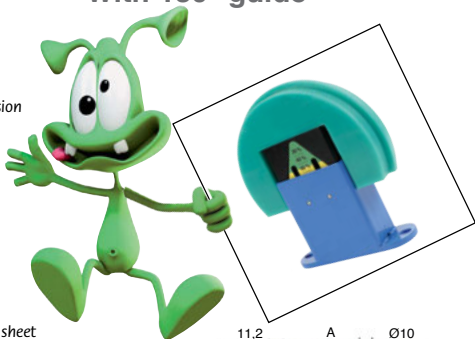

Detail A  
Pre-tensioning spring

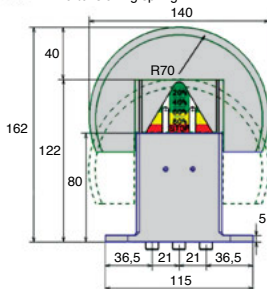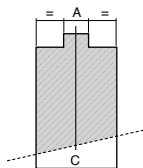

### DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Chain	A	C	Stroke	Tension (N)			Price each
					1 spring	2 springs	3 springs	
TC1-RP-06B1	06B1	5	30	40	60 to 132	120 to 264	180 to 396	211,11 €
TC1-RP-08B1	08B1	7	30	40	60 to 132	120 to 264	180 to 396	211,11 €
TC1-RP-10B1	10B1	9	30	40	60 to 132	120 to 264	180 to 396	211,11 €
TC1-RP-12B1	12B1	11	30	40	60 to 132	120 to 264	180 to 396	211,11 €

Dimensions in mm