

Fixed castor for aluminium profile

For loads up to 120kg

TPEF

- Castor for aluminium profil 40/45mm
such as PRF4545

- Materials:

Plate: powder-coated steel sheet,

natural aluminium colour

Wheel: grey polypropylene (RAL 7001)

Advantages


- Silent
- Will not mark floor
- Low rolling resistance

Info

- Fixing screws not supplied
(See PRF-ECL-M8 and BHC8/CHC8 screws)



Typical application

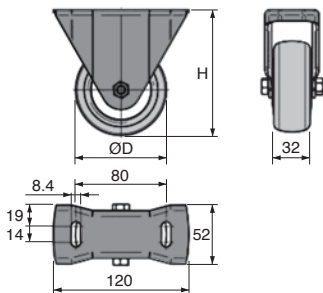

DISCOUNTS

Qty	1+	10+	30+
Disc. List	-5%	On request	

Part number	ØD	H	Maximum load (N)	Weight (g)	Price each 1 to 9
TPE80/F	80	111	1000	484	22,14 €
TPE100/F	100	136	1100	577	26,60 €
TPE125/F	125	161	1200	675	29,80 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

279