
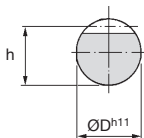


- Angolo di pressione 20°
- Diametro tolleranza h11
- Materiale:
Inox stirato 304

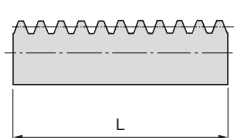

A stock
fino a modulo 2

SCONTI PER QUANTITÀ

Qtà	1+	3+	6+
Sc.	Prezzo	-10%	Su richiesta

Codice	Modulo	h (mm)	ØD (mm)	L (mm)	Prezzo unit. da 1 a 2
TRM1-1000/SS	1	9,00	10	999	121,99 €
TRM1.5-1000/SS	1,5	13,50	15	999	176,24 €
TRM2-1000/SS	2	18,00	20	999	171,48 €
TRM2.5-1000/SS	2,5	22,50	25	997	Su richiesta
TRM3-1000/SS	3	27,00	30	999	Su richiesta
TRM4-1000/SS	4	36,00	40	1005	Su richiesta
TRM5-1000/SS	5	45,00	50	1005	Su richiesta

Dimensioni in mm