

Hexagonal headed bolt with narrow shaft

VHTMHDSS

Hygienic Design®

- **Thin shaft bolts for use in hygienic environments**

- **Material:**

Stainless steel 1.4404 (316L)


Polished finish Ra<0.8

Advantages

- In combination with a clamping element, these thin shafted screws are designed against becoming detached accidentally, thus meeting the requirements of European standard 2006/42/EG
- Dirt and residues of product or cleaning materials will not remain, ensuring easy cleaning

Accessories

- **RDS** safety washer to secure the screw to the other component before assembly (see page 60)

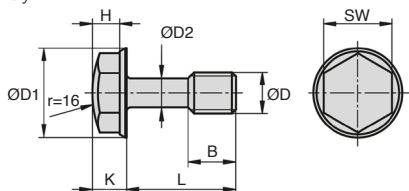

DISCOUNTS

| Qty | 1+ | 5+ | 10+ | 25+ | 50+ |
|-------|-----|-----|------|------|------------|
| Disc. | Net | -5% | -10% | -15% | On request |

| Part N° | ØD | ØD1 | ØD2 | H | B | K | L | SW | Price each |
|---------------|----|------|-----|-----|-----|-----|------|-----|------------|
| | | | | | | | | | 1 to 4 |
| VHTM4-8/HDSS | M4 | 9,2 | 3,1 | 3,0 | 5,0 | 4,0 | 8,0 | 7,0 | 6,25 € |
| VHTM4-10/HDSS | M4 | 9,2 | 3,1 | 3,0 | 5,0 | 4,0 | 10,0 | 7,0 | 6,28 € |
| VHTM4-12/HDSS | M4 | 9,2 | 3,1 | 3,0 | 5,0 | 4,0 | 12,0 | 7,0 | 6,37 € |
| VHTM4-16/HDSS | M4 | 9,2 | 3,1 | 3,0 | 5,0 | 4,0 | 16,0 | 7,0 | 6,43 € |
| VHTM4-20/HDSS | M4 | 9,2 | 3,1 | 3,0 | 5,0 | 4,0 | 20,0 | 7,0 | 6,49 € |
| VHTM5-8/HDSS | M5 | 10,5 | 3,7 | 3,7 | 6,0 | 4,7 | 8,0 | 8,0 | 6,49 € |
| VHTM5-10/HDSS | M5 | 10,5 | 3,7 | 3,7 | 6,0 | 4,7 | 10,0 | 8,0 | 6,58 € |
| VHTM5-12/HDSS | M5 | 10,5 | 3,7 | 3,7 | 6,0 | 4,7 | 12,0 | 8,0 | 6,64 € |
| VHTM5-16/HDSS | M5 | 10,5 | 3,7 | 3,7 | 6,0 | 4,7 | 16,0 | 8,0 | 6,72 € |
| VHTM5-20/HDSS | M5 | 10,5 | 3,7 | 3,7 | 6,0 | 4,7 | 20,0 | 8,0 | 6,78 € |
| VHTM5-25/HDSS | M5 | 10,5 | 3,7 | 3,7 | 6,0 | 4,7 | 25,0 | 8,0 | 6,90 € |

All dimensions in mm

| Part N° | ØD | ØD1 | ØD2 | H | B | K | L | SW | Price each 1 to 4 |
|----------------|-----|------|-----|-----|------|-----|------|------|----------------------|
| VHTM6-8/HDSS | M6 | 13,0 | 4,2 | 4,0 | 7,0 | 5,0 | 8,0 | 10,0 | 7,05 € |
| VHTM6-12/HDSS | M6 | 13,0 | 4,2 | 4,0 | 7,0 | 5,0 | 12,0 | 10,0 | 7,18 € |
| VHTM6-16/HDSS | M6 | 13,0 | 4,2 | 4,0 | 7,0 | 5,0 | 16,0 | 10,0 | 7,35 € |
| VHTM6-20/HDSS | M6 | 13,0 | 4,2 | 4,0 | 7,0 | 5,0 | 20,0 | 10,0 | 7,47 € |
| VHTM6-25/HDSS | M6 | 13,0 | 4,2 | 4,0 | 7,0 | 5,0 | 25,0 | 10,0 | 7,66 € |
| VHTM6-30/HDSS | M6 | 13,0 | 4,2 | 4,0 | 7,0 | 5,0 | 30,0 | 10,0 | 7,82 € |
| VHTM6-35/HDSS | M6 | 13,0 | 4,2 | 4,0 | 7,0 | 5,0 | 35,0 | 10,0 | 7,97 € |
| VHTM6-40/HDSS | M6 | 13,0 | 4,2 | 4,0 | 7,0 | 5,0 | 40,0 | 10,0 | 8,19 € |
| VHTM6-45/HDSS | M6 | 13,0 | 4,2 | 4,0 | 7,0 | 5,0 | 45,0 | 10,0 | 8,35 € |
| VHTM6-50/HDSS | M6 | 13,0 | 4,2 | 4,0 | 7,0 | 5,0 | 50,0 | 10,0 | 8,48 € |
| VHTM6-60/HDSS | M6 | 13,0 | 4,2 | 4,0 | 7,0 | 5,0 | 60,0 | 10,0 | 8,89 € |
| VHTM8-16/HDSS | M8 | 16,8 | 6,0 | 5,5 | 9,0 | 6,5 | 16,0 | 13,0 | 8,09 € |
| VHTM8-20/HDSS | M8 | 16,8 | 6,0 | 5,5 | 9,0 | 6,5 | 20,0 | 13,0 | 8,35 € |
| VHTM8-25/HDSS | M8 | 16,8 | 6,0 | 5,5 | 9,0 | 6,5 | 25,0 | 13,0 | 8,57 € |
| VHTM8-30/HDSS | M8 | 16,8 | 6,0 | 5,5 | 9,0 | 6,5 | 30,0 | 13,0 | 8,86 € |
| VHTM8-35/HDSS | M8 | 16,8 | 6,0 | 5,5 | 9,0 | 6,5 | 35,0 | 13,0 | 9,11 € |
| VHTM8-40/HDSS | M8 | 16,8 | 6,0 | 5,5 | 9,0 | 6,5 | 40,0 | 13,0 | 9,33 € |
| VHTM8-45/HDSS | M8 | 16,8 | 6,0 | 5,5 | 9,0 | 6,5 | 45,0 | 13,0 | 9,62 € |
| VHTM8-50/HDSS | M8 | 16,8 | 6,0 | 5,5 | 9,0 | 6,5 | 50,0 | 13,0 | 9,87 € |
| VHTM8-60/HDSS | M8 | 16,8 | 6,0 | 5,5 | 9,0 | 6,5 | 60,0 | 13,0 | 10,40 € |
| VHTM8-65/HDSS | M8 | 16,8 | 6,0 | 5,5 | 9,0 | 6,5 | 65,0 | 13,0 | 10,69 € |
| VHTM8-70/HDSS | M8 | 16,8 | 6,0 | 5,5 | 9,0 | 6,5 | 70,0 | 13,0 | 10,97 € |
| VHTM10-20/HDSS | M10 | 20,6 | 7,7 | 7,3 | 12,0 | 8,3 | 20,0 | 16,0 | 9,62 € |
| VHTM10-25/HDSS | M10 | 20,6 | 7,7 | 7,3 | 12,0 | 8,3 | 25,0 | 16,0 | 9,99 € |
| VHTM10-30/HDSS | M10 | 20,6 | 7,7 | 7,3 | 12,0 | 8,3 | 30,0 | 16,0 | 10,37 € |
| VHTM10-35/HDSS | M10 | 20,6 | 7,7 | 7,3 | 12,0 | 8,3 | 35,0 | 16,0 | 10,75 € |
| VHTM10-40/HDSS | M10 | 20,6 | 7,7 | 7,3 | 12,0 | 8,3 | 40,0 | 16,0 | 11,16 € |
| VHTM10-45/HDSS | M10 | 20,6 | 7,7 | 7,3 | 12,0 | 8,3 | 45,0 | 16,0 | 11,57 € |
| VHTM10-50/HDSS | M10 | 20,6 | 7,7 | 7,3 | 12,0 | 8,3 | 50,0 | 16,0 | 11,96 € |
| VHTM10-60/HDSS | M10 | 20,6 | 7,7 | 7,3 | 12,0 | 8,3 | 60,0 | 16,0 | 12,79 € |
| VHTM10-70/HDSS | M10 | 20,6 | 7,7 | 7,3 | 12,0 | 8,3 | 70,0 | 16,0 | 13,65 € |
| VHTM10-80/HDSS | M10 | 20,6 | 7,7 | 7,3 | 12,0 | 8,3 | 80,0 | 16,0 | 14,54 € |

All dimensions in mm