


- **Volantino zigrinato**
- Elementi di manovra
- Materiale:
Inox 303 lucidato
- A norma DIN 464
- **Per questa lunghezza, il volantino zigrinato è consegnato con perno filettato completo (nessuna gola di scarico)

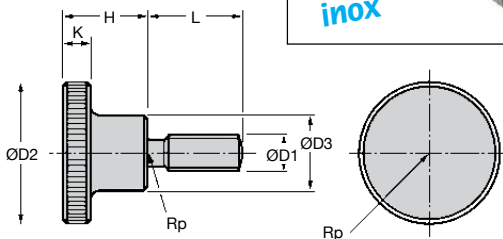

SCONTI PER QUANTITÀ

Qtà	1+	6+	20+	40+	60+	101+
Sc.	Prezzo	-10%	-15%	-20%	-25%	Su richiesta

Codice	ØD1	ØD2	ØD3	H	K	L	Stock*	Prezzo unit. da 1 a 5
VMS4-10	M4	16	8	9,5	3,5	10	✓	2,56 €
VMS4-16	M4	16	8	9,5	3,5	16	✓	2,84 €
VMS4-20	M4	16	8	9,5	3,5	20**	✓	3,10 €
VMS5-10	M5	20	10	11,5	4,0	10	✓	3,16 €
VMS5-16	M5	20	10	11,5	4,0	16	✓	3,75 €
VMS5-20	M5	20	10	11,5	4,0	20**	✓	4,53 €
VMS6-10	M6	24	12	15,0	5,0	10	✓	6,80 €
VMS6-16	M6	24	12	15,0	5,0	16	✓	5,29 €
VMS6-20	M6	24	12	15,0	5,0	20	✓	9,59 €
VMS6-25	M6	24	12	15,0	5,0	25**	✓	7,78 €
VMS8-16	M8	30	16	18,0	6,0	16	✓	12,12 €
VMS8-20	M8	30	16	18,0	6,0	20	✓	13,15 €
VMS8-25	M8	30	16	18,0	6,0	25	✓	12,48 €
VMS10-20	M10	36	20	23,0	8,0	20	✓	18,46 €
VMS10-25	M10	36	20	23,0	8,0	25	✓	20,77 €

*Nei limiti delle disponibilità - Dimensioni in mm