

# Female swivelling lifting rings

## Rotating eye ring


**RUD® VRM**

- When considering the VRM (Female lifting ring), please also read the information on the VRS.
- Captive nut, 100% tested for cracks
- The male thread must be in contact with 100% of the thread of the nut. During assembly verify that load is in contact with the full surface of the base of the VRM nut.
- The values of load given are only valid when the recommended male thread (category 10.9 minimum) is used.
- When fully screwed in, the ring must be able to rotate through 360°.
- **Attention:** Read the instruction notice carefully.



### Info

- Conforms to European Directive 98/37/CE
- The nominal SWL engraved on the ring is valid for pulling in all directions

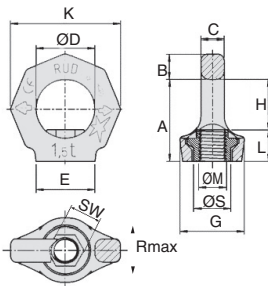

### DISCOUNTS

Qty	1+	5+	10+	15+
Disc.	List	-3%	-6%	On request

**CE**

Part number	SWL	ØM	A	B	C	ØD	E	G	H	K	L	Rmax	ØS	SW	Weight (kg)	Price each
																1 to 4
VRM-M6	0,1t	M6	28	9	7	20	23	28	17	37	11	16	13	9	0,05	74,32 €
VRM-M8	0,3t	M8	35	11	9	25	25	30	21	47	14	21	16,3	12	0,10	56,27 €
VRM-M10	0,4t	M10	35	11	9	25	25	30	21	47	14	21	16,3	12	0,10	66,57 €
VRM-M12	0,75t	M12	42	13	10	30	30	34	25	56	17	24	19,8	14	0,20	71,56 €
VRM-M16	1,5t	M16	49	15	13	35	36	40	31	65	21	30	23,6	19	0,30	91,57 €
VRM-M20	2,3t	M20	58	17	16	40	41	50	35	76	23	37	29,3	24	0,50	104,65 €
VRM-M24	3,2t	M24	70	20	19	49	51	60	41	92	29	45	35,2	30	0,90	130,05 €
VRM-M30	4,5t	M30	87	26	24	60	66	75	51	114	36	56	44	36	1,50	182,40 €

\*Depending on availability - Dimensions in mm