


# Hexagonal headed bolts, **DIN 933**

**New****VTH****Zinc plated steel (Class 8.8)**

- Bolt conforming to DIN 933
- Full thread
- Material:
  - Zinc plated steel (Class 8.8)
- Mechanical characteristics conform to ISO 898-1
- Supplied by the packet

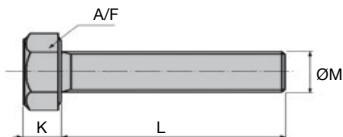

## DISCOUNTS

No. packets	1+	6+	20+	50+
Discounts	List	-5%	-20%	On request

Part number	ØM	Pitch		K	A/F across flats	Qty per packet	Price each
		P	L				1 to 5
VTH4-10/B	M4	0,70	10	2,92	7,0	500	11,28 €
VTH4-12/B	M4	0,70	12	2,92	7,0	500	12,42 €
VTH4-16/B	M4	0,70	16	2,92	7,0	500	14,68 €
VTH4-20/B	M4	0,70	20	2,92	7,0	500	16,56 €
VTH4-25/B	M4	0,70	25	2,92	7,0	500	19,56 €
VTH4-30/B	M4	0,70	30	2,92	7,0	500	22,19 €
VTH4-35/B	M4	0,70	35	2,92	7,0	200	13,84 €
VTH4-40/B	M4	0,70	40	2,92	7,0	200	15,51 €
VTH5-10/B	M5	0,80	10	3,65	8,0	500	11,43 €
VTH5-12/B	M5	0,80	12	3,65	8,0	500	12,64 €
VTH5-16/B	M5	0,80	16	3,65	8,0	500	14,74 €
VTH5-20/B	M5	0,80	20	3,65	8,0	500	16,87 €
VTH5-25/B	M5	0,80	25	3,65	8,0	500	19,56 €
VTH5-30/B	M5	0,80	30	3,65	8,0	500	22,28 €
VTH5-35/B	M5	0,80	35	3,65	8,0	200	10,01 €
VTH5-40/B	M5	0,80	40	3,65	8,0	200	11,06 €
VTH5-45/B	M5	0,80	45	3,65	8,0	200	15,20 €
VTH5-50/B	M5	0,80	50	3,65	8,0	200	16,84 €

Dimensions in mm

## DISCOUNTS

No. packets	1+	6+	20+	50+
Discounts	List	-5%	-20%	On request

Part number	ØM	Pitch			A/F across flats	Qty per packet	Price each 1 to 5
		P	L	K			
VTH6-10/B	M6	1,00	10	4,15	10,0	500	22,19 €
VTH6-16/B	M6	1,00	16	4,15	10,0	500	18,69 €
VTH6-20/B	M6	1,00	20	4,15	10,0	500	21,07 €
VTH6-25/B	M6	1,00	25	4,15	10,0	500	24,23 €
VTH6-30/B	M6	1,00	30	4,15	10,0	500	27,38 €
VTH6-40/B	M6	1,00	40	4,15	10,0	200	13,50 €
VTH6-50/B	M6	1,00	50	4,15	10,0	200	16,04 €
VTH6-60/B	M6	1,00	60	4,15	10,0	200	21,20 €
VTH8-20/B	M8	1,25	20	5,45	13,0	200	17,09 €
VTH8-30/B	M8	1,25	30	5,45	13,0	200	21,51 €
VTH8-40/B	M8	1,25	40	5,45	13,0	100	13,01 €
VTH8-50/B	M8	1,25	50	5,45	13,0	100	15,11 €
VTH8-60/B	M8	1,25	60	5,45	13,0	100	17,40 €
VTH8-70/B	M8	1,25	70	5,45	13,0	100	19,59 €
VTH8-80/B	M8	1,25	80	5,45	13,0	100	21,82 €
VTH10-20/B	M10	1,50	20	6,58	17,0	200	29,51 €
VTH10-30/B	M10	1,50	30	6,58	17,0	200	36,46 €
VTH10-40/B	M10	1,50	40	6,58	17,0	100	21,66 €
VTH10-50/B	M10	1,50	50	6,58	17,0	100	25,12 €
VTH10-60/B	M10	1,50	60	6,58	17,0	50	14,37 €
VTH10-70/B	M10	1,50	70	6,58	17,0	50	16,10 €
VTH10-80/B	M10	1,50	80	6,58	17,0	50	17,83 €
VTH10-100/B	M10	1,50	100	6,58	17,0	50	21,29 €
VTH12-20/B	M12	1,75	20	7,68	19,0	100	21,54 €
VTH12-35/B	M12	1,75	35	7,68	19,0	100	28,71 €
VTH12-45/B	M12	1,75	45	7,68	19,0	100	33,71 €
VTH12-55/B	M12	1,75	55	7,68	19,0	50	19,31 €
VTH12-60/B	M12	1,75	60	7,68	19,0	50	20,24 €
VTH12-70/B	M12	1,75	70	7,68	19,0	50	23,08 €
VTH12-80/B	M12	1,75	80	7,68	19,0	50	25,59 €
VTH12-100/B	M12	1,75	100	7,68	19,0	50	30,59 €

Dimensions in mm