






- Materiale:

Alluminio anodizzato duro

- Lunghezza standard: 1.000mm

Opzione: possibile fino a 4.000mm

- Per carrello **WJUM16** e **WJRM16**

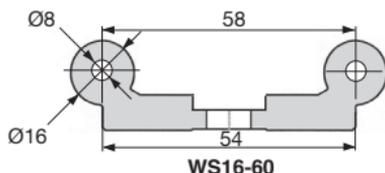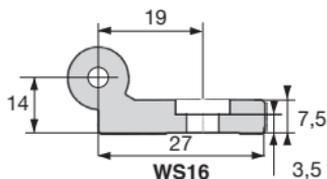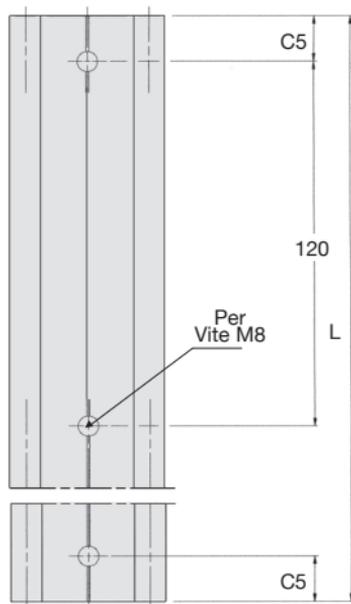

Modulabile

SCONTI PER QUANTITÀ

Qtà	1+	5+	10+	15+	20+
Sc.	Prezzo	-10%	-15%	-20%	Su richiesta

Codice	Lunghezza		C5 mini	C5 max.	Iy (mm ⁴)	Iz (mm ⁴)	Wby (mm ³)	Wbz (mm ³)	Massa (kg/m)	Prezzo unit. da 1 a 4
	L (mm)	L max. (mm)								
WS16	1000	4000	20	79,5	36000	12900	1800	940	0,98	✓ 94,51 €
WS16-60	1000	4000	20	79,5	36760	26100	9900	1900	1,96	✓ 200,23 €

*Nei limiti delle disponibilità - Dimensioni in mm