






**- Materiale:**

- Alluminio anodizzato duro
- Lunghezza standard: 1.000mm
- Opzione: possibile fino a 4.000mm
- Per carrello **WJUM20** e **WJRM20**



**Modulabile**

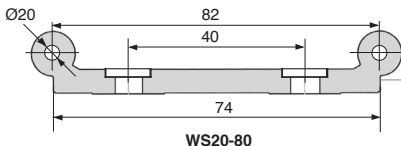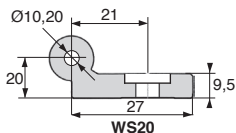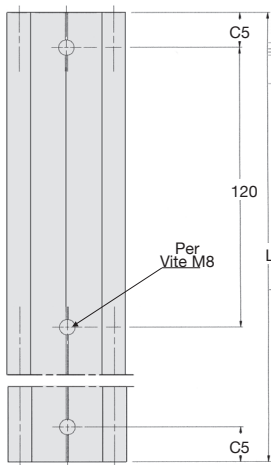

### SCONTI PER QUANTITÀ

| Qtà | 1+     | 5+   | 10+  | 15+  | 20+          |
|-----|--------|------|------|------|--------------|
| Sc. | Prezzo | -10% | -15% | -20% | Su richiesta |

| Codice  | Lunghezza |             | C5 mini | C5 max. | Iy (mm <sup>4</sup> ) | Iz (mm <sup>4</sup> ) | Wby (mm <sup>3</sup> ) | Wbz (mm <sup>3</sup> ) | Massa (kg/m) | Stock* | Prezzo unit. da 1 a 4 |
|---------|-----------|-------------|---------|---------|-----------------------|-----------------------|------------------------|------------------------|--------------|--------|-----------------------|
|         | L (mm)    | L max. (mm) |         |         |                       |                       |                        |                        |              |        |                       |
| WS20    | 1000      | 4000        | 20      | 79,5    | 9000                  | 2850                  | 1000                   | 310                    | 1,32         | ✓      | 110,61 €              |
| WS20-80 | 1000      | 4000        | 20      | 79,5    | 108000                | 78700                 | 21000                  | 4000                   | 3,30         | ✓      | 235,33 €              |

\*Nei limiti delle disponibilità - Dimensioni in mm