

Door stop for aluminium profile




Magnetic closing

ACLAPB

- **Quick door closing system**
- **Materials:**
 - Glass fibre reinforced PA plastic
 - Neodymium magnet
 - Steel counter plate and screws

Advantages

- Discrete stop
- Small size, takes up little space inside the machine

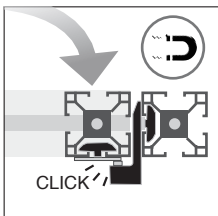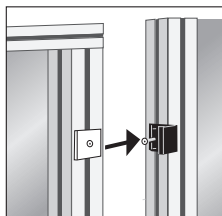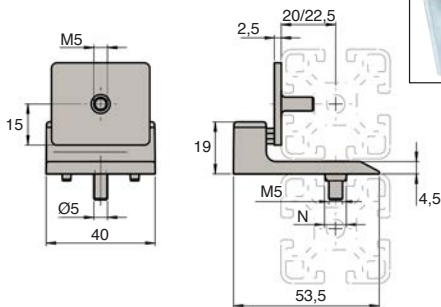

Typical application

DISCOUNTS

| Qty | 1+ | 50+ | 100+ |
|-------|-----|-----|------------|
| Disc. | Net | -5% | On request |

| Part N° | N | Holding force (N) | Weight (g) | Price each 1 to 49 |
|------------|------|-------------------|------------|--------------------|
| ACL-APB-53 | 8/10 | 30 | 53 | 12,30 € |

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

239

Altri prodotti...



WJUM20

Pattino Drylin® W,
Pattino



BUT

Accessori per
pannello, Arresto per
pannello



CHMR50

Riduttore a ruota e
vite senza fine, fino a
107 Nm



EC2

Panamech, Multi-
Beam, Alluminio - con
ganascia di serraggio



SLH

Attrezzo di bloccaggio
a leva orizzontale, A
leva orizzontale -
acciai...



SVR5

Martinetto a vite - Vite
rotante, Con
madrevite esterna



BOX-TOR-B

Valigetta di
guarnizioni toriche in
nitrile, 20.38 x
1.78mm a 50.16 ...



EMAS

Antistatic knurled nut,
Antistatic



IN2

Ingranaggio interno,
Plastica lavorata
(delrin)



SFE

Testa a snodo
femmina, Inox / PTFE



GMC_GMK_BR

Morsetto porta guide,
Piatto o tondo



PO

Maniglia a ponte -
Multi-settore, Foro
liscio

Prodotti correlati



ACLAPA

Sistema di chiusura,
Battuta a calamita



ACLDBB

Sistema di chiusura
per profili alluminio,
Fermo a 2 sfere