

# Door stop for aluminium profile



## Magnetic closing

## ACLAPB

- **Quick door closing system**
- **Materials:**
  - Glass fibre reinforced PA plastic
  - Neodymium magnet
  - Steel counter plate and screws

### Advantages

- Discrete stop
- Small size, takes up little space inside the machine

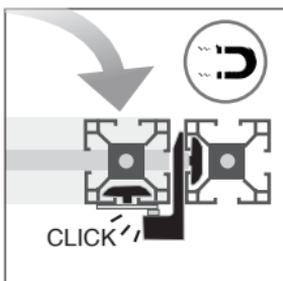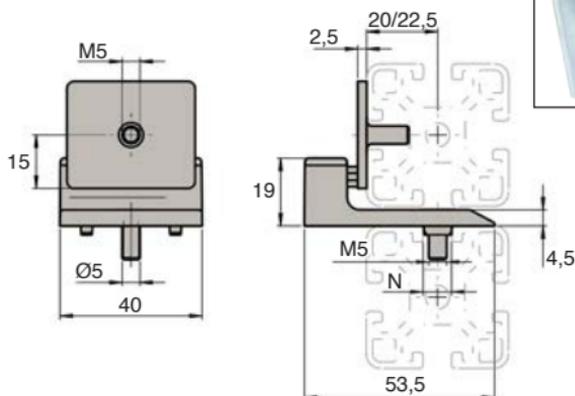

Typical application

### DISCOUNTS

Qty	1+	50+	100+
Disc.	Net	-5%	On request

Part N°	N	Holding force (N)	Weight (g)	Price each 1 to 49
ACL-APB-53	8/10	30	53	12,30 €

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

239

## Altri prodotti...



CMAss

Vite ad occhiello, Inox



NCT

Giunto di collegamento, Ad angolo fisso



FBL4004\_K32

Spazzola al metro, Polipropilene nero striato (PP)



BABreglable

Perno autobloccante, Regolabile



WW16

Carrello Drylin® W, Carrello



B3PAN

Panamech, Multi-Beam inox, Inox - con ganascia di serraggio



ZG0

Ingranaggio dritto in plastica, Plastica lavorata (delrin)



BPP

Supporto ritto in lamiera con cuscinetto, Lamiera



DP

Spina cilindrica, standard ISO 2338



RPCtc

Ruota girevole a foro centrale, Acciaio - Poliammide



DCG

Ventosa, nitrile



CHMR75

Riduttore a ruota e vite senza fine, fino a 298 Nm

## Prodotti correlati



ACLAPA

Sistema di chiusura, Battuta a calamita



ACLBDB

Sistema di chiusura per profili alluminio, Fermo a 2 sfere