

Panel mounting block for aluminium structures New

ACL_{FPA} Angular joint and mounting block

- Support for glazed panel, multiple blocks can be used to create angled joints

- Materials:

- Injection moulded zinc, aluminium sprayed coating
- Block supplied with 5 rubber pads for panel thicknesses from 2 to 5 mm

Assembly


- Insert the PRF-ECL-M5 nut (supplied separately) into the slot of the aluminium profile.
- Attach the first side of the block using the M5 screw supplied.
- Attach the rubber mounting pads
- Tighten the second side of the mounting block
- When creating an angled joint, attach the first sides of each block, then attach the rubber mounting pads and then fix the second sides.




ACL-FPA-BM



ACL-FPA-RA

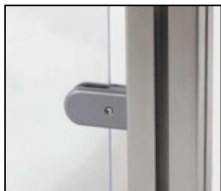


Typical application
ACL-FPA-BM

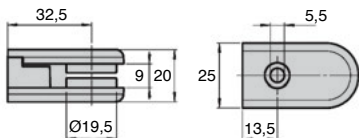

ACL-FPA-BM



ACL-FPA-BM + ACL-FPA-RA

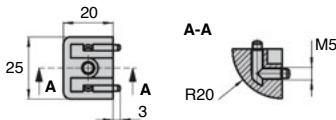

ACL-FPA-RA

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Weight (g)	Price each 1 to 49
ACL-FPA-BM	Support bloc	74	9,74 €
ACL-FPA-RA	Angular joint	37	6,02 €

Dimensions in mm

Altri prodotti...



KITbuh
Kit di motorizzazione
24V, Planetario



PR40
Piede fissabile con
snodo - poliammide, Ø
50




CLM
Attacco per forcella,
Corta acciaio



PRF_PL_4590
Elementi di giunzione,
Piastra di giunzione -
45x90 mm



SHTP
Tavola lineare
Drylin®, Economica

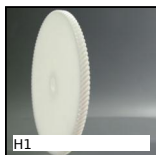


H1
Ingranaggio elicoidale
ad assi incrociati a
90°, Plastica lavorata



H2
Ingranaggio elicoidale
ad assi incrociati a
90°, Plastica lavorata



PW_PWG3
Ruota di precisione,
Bronzo

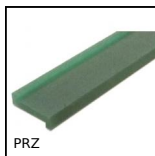


PRZ
Profilo supporto per
catena, Profilo a Z ad
incastro



VCMB
Vite di giunzione
metallo/legno, Acciaio



PRS50
Piede snodato tutto
inox Ø50, Ø 50

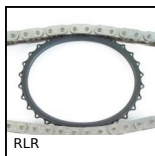

RLR
Tenditore per catene
Roll-Ring®, Roll-
Ring® Self-adjusting

Prodotti correlati



PRF_ECL
Fissaggio, Dado
quadrato con
linguetta - Acciaio



ACL-FPA
Accessori per pannelli,
Morsetto angolare