

Connection plate for aluminium profile

ACLPL For pre-assembled connection

- For connecting two structures together
- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:
Anodised aluminium

Info.



- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)




Typical application

Anodised aluminium

Aluminium profile

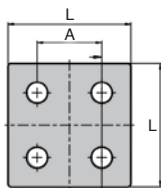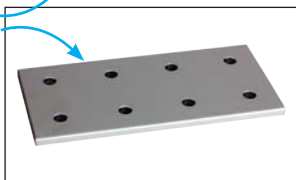

ACL-PL-9090

 

ACL-PL-90180

DISCOUNTS

Qty	1+	50+	100+
Disc.	Net	-5%	On request

Part N°	L	B	H	A	ØD	Weight (g)	Price each 1 to 49
Square							
ACL-PL-9090	86	-	6	45	9	115	6,63 €
Rectangular							
ACL-PL-90180	176	86	6	45	9	240	11,30 €

All dimensions in mm

Altri prodotti...



F7-1

Visualizzatore multifunzione, Con sensore di posizione integrato



PTA150

Piede snodato con base stampata Ø150, Ø 150



RDE-B

Rondella di tenuta Hygienic Usit®, Stainless steel - EPDM blu



RTE

Rotex®, elastico, acciaio



YG1

Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6



BC3

Panamech, Multi-Beam inox, Inox - con ganascia di serraggio



RCC_RCX

Rondella sferica - DIN6319, convessa



PW_PWG25

Ruota di precisione, Bronzo



HAS

Rondella girevole, Vite con spalla a testa



ZG3

Ingranaggio dritto in plastica, Plastica



NPR

Morsetto porta catarifrangente,



DCG

Ventosa, silicone

Prodotti correlati



BHC

Vite a testa bombata BHC , Inox A2



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Inox



ACL-PL

Elementi di giunzione, Piastra di fissaggio - 176x86 mm



ACL-PLAngle

Elementi di giunzione, Collegamento angolare