

Connection plate for aluminium profile

ACLPL For pre-assembled connection

- For connecting two structures together
- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:
Anodised aluminium

Info.



- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)





Typical application

Anodised aluminium

Aluminium profile

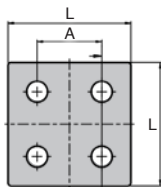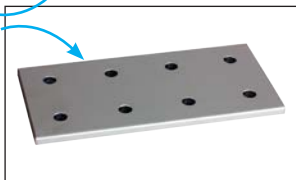

ACL-PL-9090

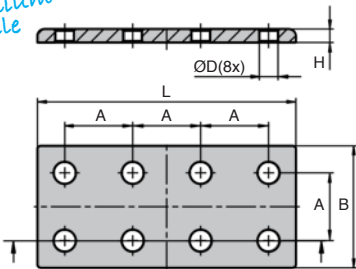 

ACL-PL-90180


DISCOUNTS

Qty	1+	50+	100+
Disc.	Net	-5%	On request

Part N°	L	B	H	A	ØD	Weight (g)	Price each 1 to 49
Square							
ACL-PL-9090	86	-	6	45	9	115	6,63 €
Rectangular							
ACL-PL-90180	176	86	6	45	9	240	11,30 €

All dimensions in mm

Altri prodotti...

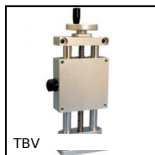

TBV
Tavola di
posizionamento
verticale manuale,
12kg



PTA50
Piede snodato con
base stampata Ø50,
4000N




PDM_PDV
Detectable plastic
palm grip, blue
thermoplastic



YG1
Ingranaggio dritto
PRESTAZIONE, Acciaio
35NCD6



GLT3E-50
Guide telescopiche
acciaio, Estensione
extra

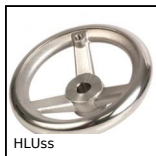

HLUss
Volantino a razze,
Inox 316



HAS
Rondella girevole, Vite
con spalla a testa
piatta con intaglio



CHV
Motovariatore
meccanico, da 0,18 a
1,5kW



CHT
Motore AC asincrono
trifase, 0.09kW



CMAss
Vite ad occhio, Inox



ACLERP
Rulliera, Con guida
laterale



TCL-ECL
Piede massiccio per
carichi pesanti, Vite a
registro

Prodotti correlati



BHC
Vite a testa bombata
BHC , Inox A2



PRF_ECL
Fissaggio, Dado
quadrato con
linguetta - Inox



ACL-PL
Elementi di giunzione,
Piastra di fissaggio -
86x86 mm



ACL-PLAngle
Elementi di giunzione,
Collegamento
angolare