

Connection plate for aluminium profile



Angle connection

ACLPL

- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:
Anodised aluminium

Info.




- Supplied without fixing kit (see button head screw BHC8-16/SS/B or BHC8-20/SS and slot nut PRF-ECL-M8/SS)

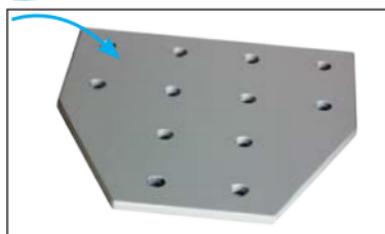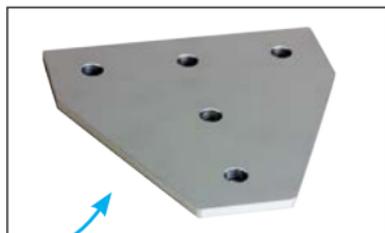

Anodised aluminium



 Typical application

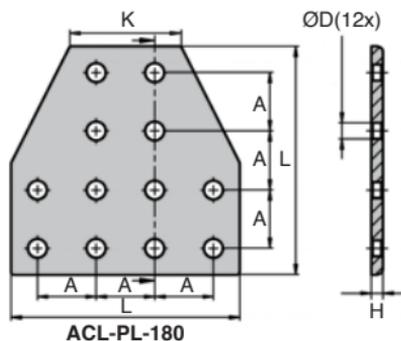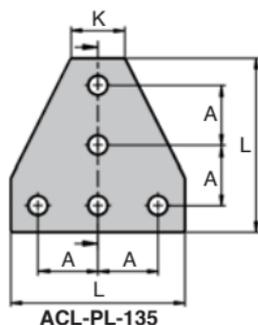

DISCOUNTS

Qty	1+	50+	100+
Disc. Net		-5%	On request

Part N°	L	H	A	K	ØD	Weight (g)	Price each
ACL-PL-135	131	6	45	41	9	210	14,57 €
ACL-PL-180	176	6	45	86	9	425	23,94 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

243

Altri prodotti...



TS01_TW01
Guida lineare su binario Drylin® T, fino a 7000 N




BPP
Supporto ritto in lamiera con cuscinetto, Lamiera



BAG
Anello di bloccaggio in acciaio, Acciaio



MRAeco
Maglia rapida economica, Acciaio

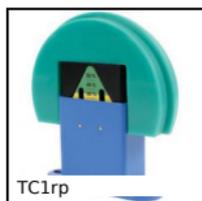

TC1rp
Tenditore per catena automatico, Con pattino 180°



GMK17_R
Guida prodotto laterale tonda, Per imbottigliamento e imballaggio




BG
Giunto Oldham, con vite a pressione



LC
Limitatore di coppia ad attrito, 190 a 1800 Nm



VTHbr
Vite a testa esagonale - DIN933, Ottone

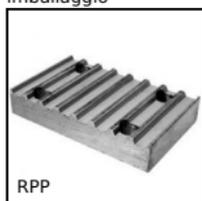

RPP
Piastra di giunzione per cinghia RPP, RPP5



BPL
Sfera portante con flangia, Leggero



CHML40
Riduttore a ruota e vite senza fine, fino a 57 Nm - Con limitatore d...

Prodotti correlati



BHC
Vite a testa bombata BHC, Inox A2



PRF_ECL
Fissaggio, Dado quadrato con linguetta - Inox