

Connection plate for aluminium profile



Angle connection

ACLPL

- Connection of 2 aluminium profiles
- Corner reinforcement
- Material:
Anodised aluminium

Info.


- Supplied without fixing kit (see button head screw BHC8-16/SS/B or BHC8-20/SS and slot nut PRF-ECL-M8/SS)

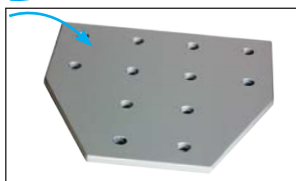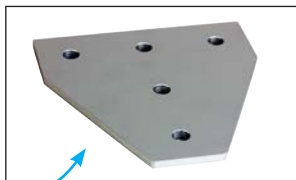


Anodised aluminium



Typical application

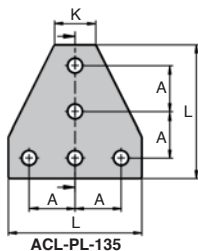

ACL-PL-135

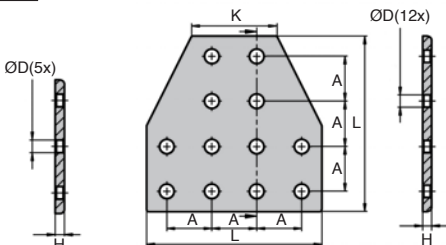

ACL-PL-180

DISCOUNTS

Qty	1+	50+	100+
Disc. Net		-5%	On request

Part N°	L	H	A	K	ØD	Weight (g)	Price each
ACL-PL-135	131	6	45	41	9	210	14,57 €
ACL-PL-180	176	6	45	86	9	425	23,94 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

243

Altri prodotti...



CPAS-H

Squadra pieghevole,
Per carico pesante



BOXKU

Box kit di chiavette a
disco, Box kit di
chiavette a disco -
acciaio



MEB

Ingranaggio conico in
plastica stampata, 1:1



GMK17_R

Guida prodotto
laterale tonda, Per
imbottigliamento e
imballaggio



AT10courroie

Cinghia di
posizionamento AT,
AT10 Poliuretano
armatura in acciaio



COA-COG

Staffa di montaggio
per molla a gas,
Staffa di montaggio
piana per s...



BAG0

Anello di bloccaggio,
Inox



CHMR110

Riduttore a ruota e
vite senza fine, fino a
980 Nm



BPL

Sfera portante con
flangia, Leggero



EHD08-3

Riduttore coassiale,
da 20 a 50 Nm



DILC

Indexing plunger with
cam, with cam



PSG08

Ingranaggio dritto di
precisione, Acciaio
20NCD2 cementato
temprato

Prodotti correlati



BHC

Vite a testa bombata
BHC , Inox A2



PRF_ECL

Fissaggio, Dado
quadrato con
linguetta - Inox